




Connection cable

VDOGH040MSS00,6A04STGH040MSS

Article no longer available - archive entry

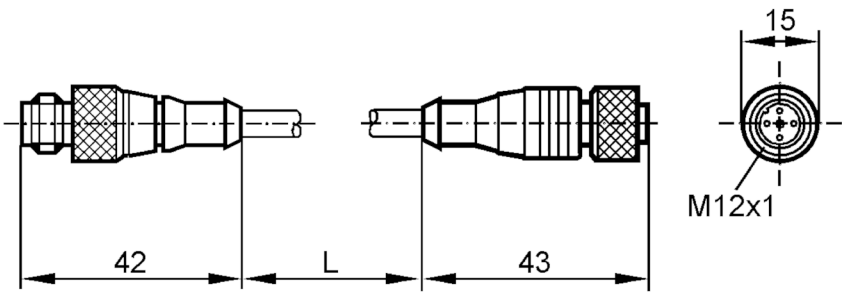

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 42
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



E10463




Connection cable

VDOGH040MSS00,6A04STGH040MSS

Electrical connection

Cable: 0.6 m, PUR / PVC; 4 x 0.25 mm²

Connection

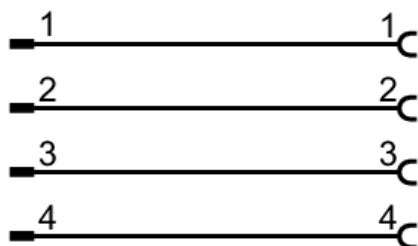

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

