

E10494




Connecting cable with socket

ADOAH042ZDS0002A03

Article no longer available - archive entry

Alternative articles: EVC007
When selecting an alternative article and accessories please note that technical data may differ!

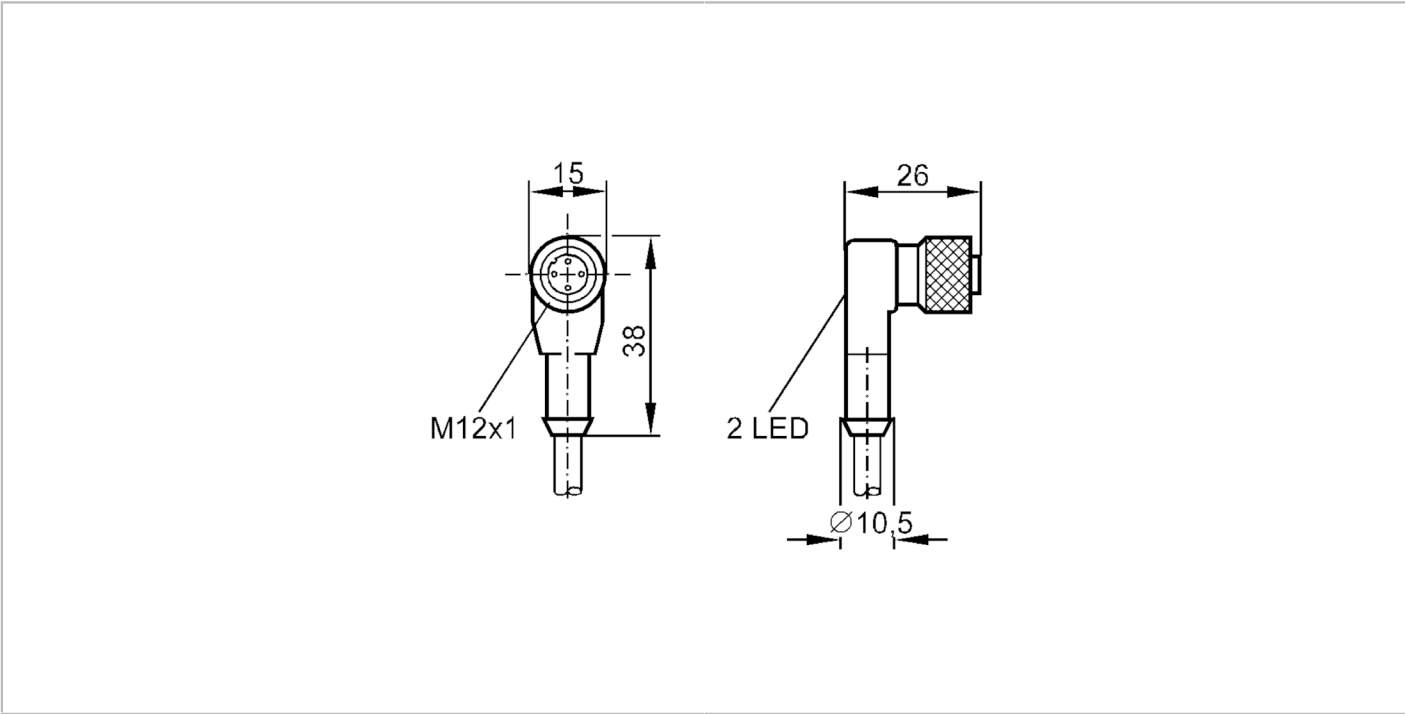

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	26 x 15 x 38
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10494



Connecting cable with socket

 
ADOAH042ZDS0002A03

Electrical connection

Cable: 2 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc



Connection



BN =	Core colours :
BK =	brown
BU =	black
	blue