

E10511




Connecting cable with socket

ADOAH042MSS0002F03

Article no longer available - archive entry

Alternative articles: E10912
When selecting an alternative article and accessories please note that technical data may differ!

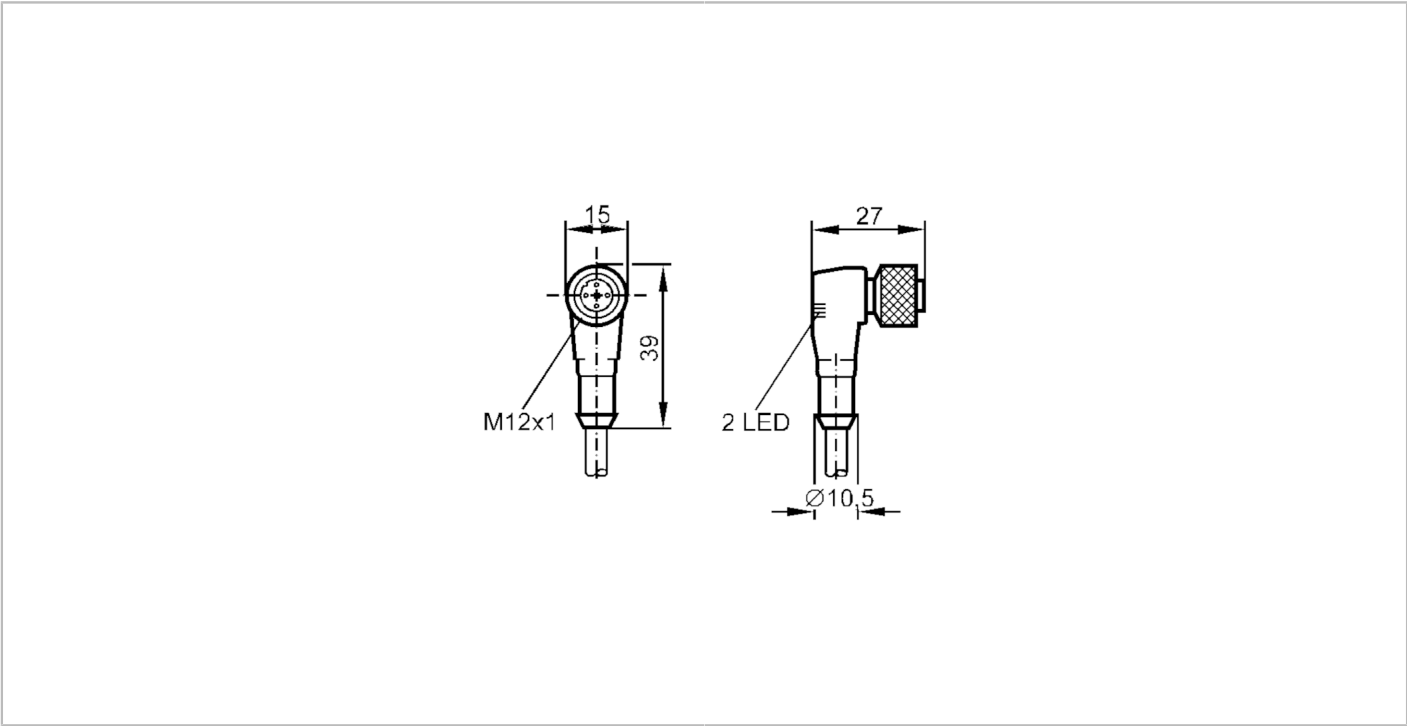

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials		TPU transparent
Moulded-body material		TPU, transparent
Material nut		brass, anti-spatter
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10511



Connecting cable with socket

ADOAH042MSS0002F03

Electrical connection

Cable: 2 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, anti-spatter



Connection



BN =	Core colours :
BK =	brown
BU =	black
	blue