


Connection cable

VDOAH042MSS00,6A03STGH030MSS

Article no longer available - archive entry

Alternative articles: EVC051

When selecting an alternative article and accessories please note that technical data may differ!

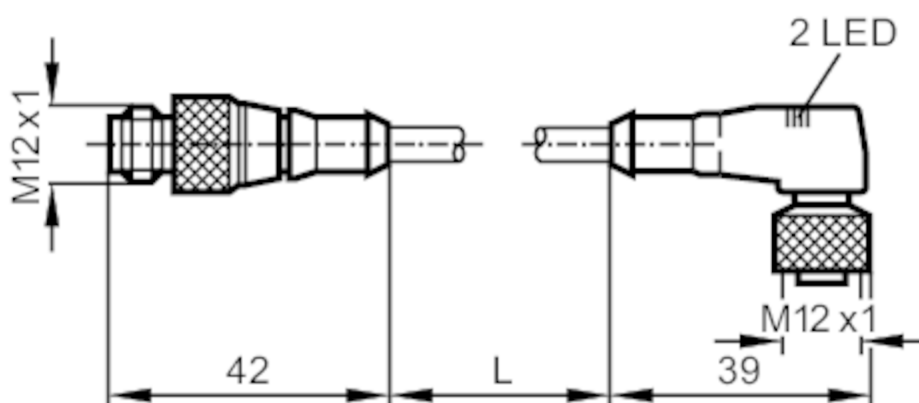

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10527



Connection cable

VDOAH042MSS00,6A03STGH030MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.6 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (180 x Ø 0.05 mm)

Connection

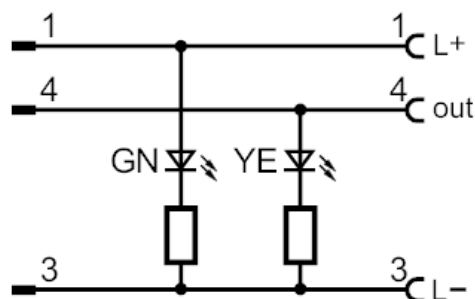

Core colours :
BK = black
BN = brown
BU = blue

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

