


Connecting cable with socket

ADOGH040MSS0015E03

Article no longer available - archive entry

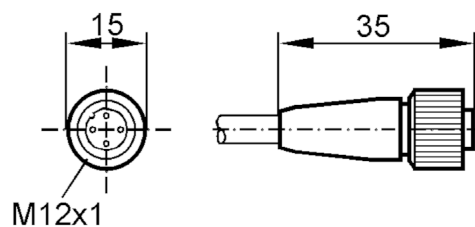

Electrical data

Operating voltage	[M]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-20...70
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	15 x 15 x 35
------------	------	--------------

Materials	PA 6.6
-----------	--------

Moulded-body material	PA 6.6
-----------------------	--------

Material nut	POM
--------------	-----

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 15 m, PVC, yellow, Ø 5.84 mm; 3 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: POM



E10559



Connecting cable with socket

ADOGH040MSS0015E03

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue