

E10561




Connecting cable with socket

ADOAH042MSS0010E03

Article no longer available - archive entry

Alternative articles: E10635
When selecting an alternative article and accessories please note that technical data may differ!

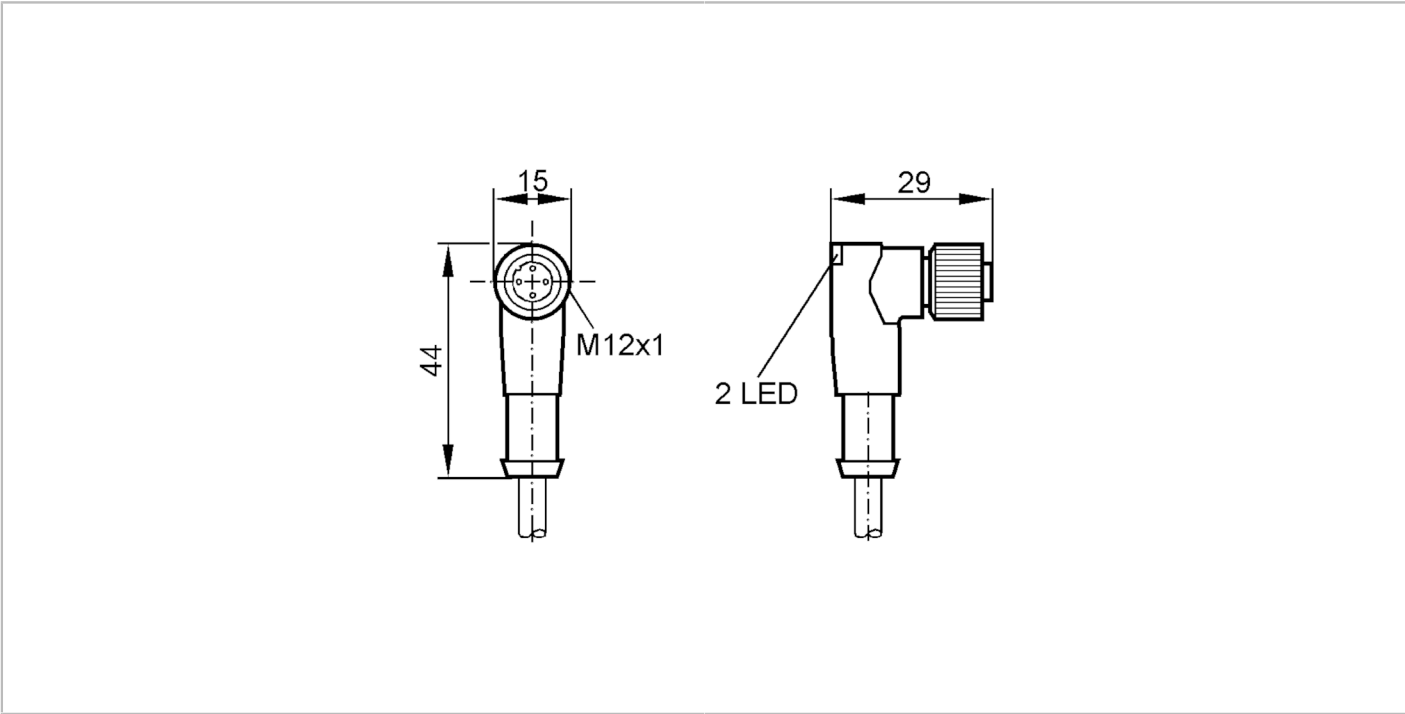

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-20...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	29 x 15 x 44
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		brass, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10561



Connecting cable with socket

ADOAH042MSS0010E03

Electrical connection


Cable: 10 m, PVC, orange, Ø 4.5 mm; cross-linked; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: brass, nickel-plated



Connection

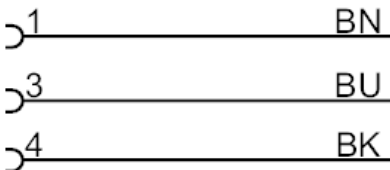

BN =	Core colours :
BK =	brown
BU =	black
	blue