

E10562




Connection cable

VDOAH042MSS0001F03STGH040MSS

Article no longer available - archive entry

Alternative articles: E10633

When selecting an alternative article and accessories please note that technical data may differ!

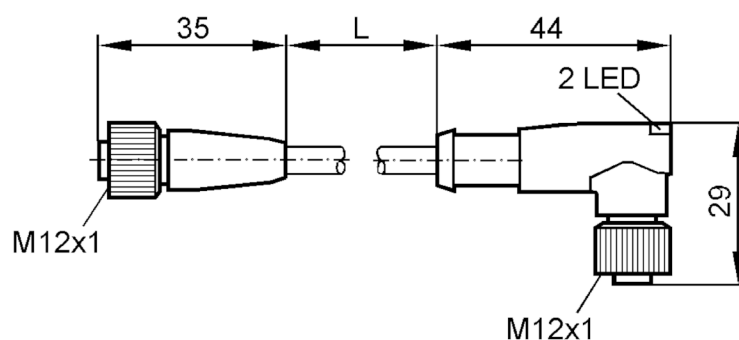

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -20...70

Protection IP 67

Mechanical data

Materials PA 6.6

Moulded-body material PA 6.6

Material nut aluminium, black anodised

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10562



Connection cable

VDOAH042MSS0001F03STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised



Electrical connection

Cable: 1 m, PVC, orange; cross-linked; 3 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised

