

E10614




Connection cable

VDOAF032ZDS00,3A03STGH030ZDS

Article no longer available - archive entry

Alternative articles: E11386

When selecting an alternative article and accessories please note that technical data may differ!

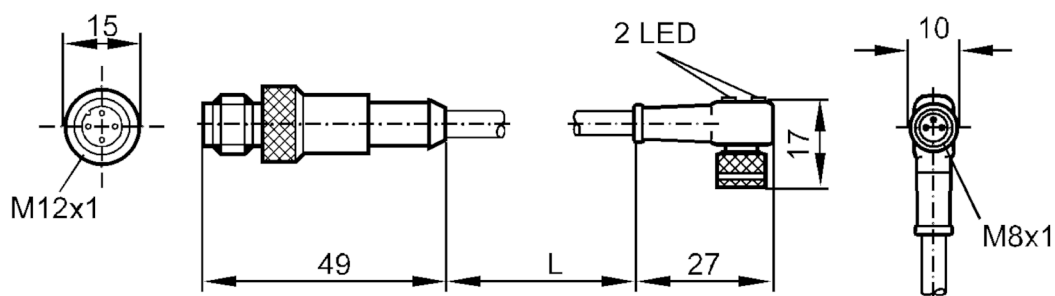

Electrical data

Operating voltage [V] 10...30 DC

Protection class III

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

Mechanical data

Dimensions [mm] 15 x 15 x 46

Materials PUR

Moulded-body material PUR

Material nut diecast zinc, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10614



Connection cable

VDOAF032ZDS00,3A03STGH030ZDS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



 
Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Connection



Electrical connection - Buchse



Connection



E10614



Connection cable

VDOAF032ZDS00,3A03STGH030ZDS

Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: diecast zinc, nickel-plated