


E10617



Connection cable

VDOAF032ZDS00,6A03STGH030ZDS

Article no longer available - archive entry

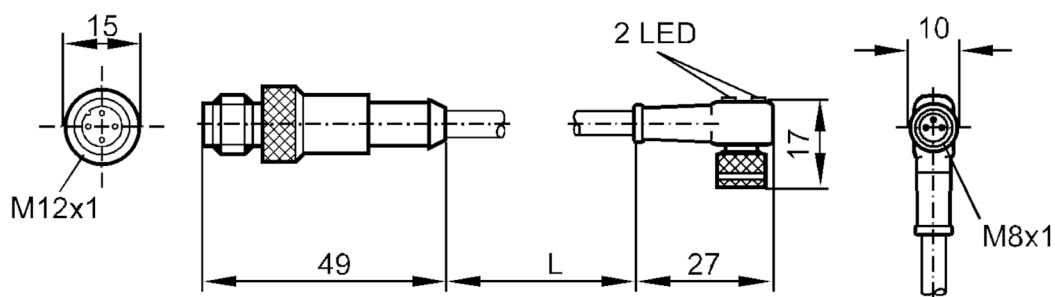

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	15 x 15 x 46
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Connection cable

VDOAF032ZDS00,6A03STGH030ZDS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)


Connection

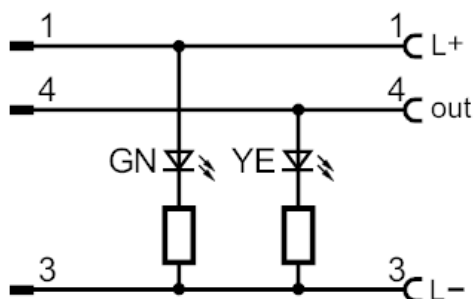

Electrical connection - Buchse



Connection

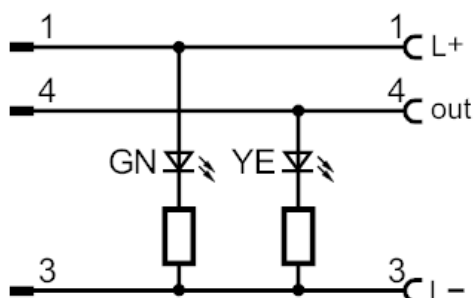

E10617



Connection cable

VDOAF032ZDS00,6A03STGH030ZDS

Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: diecast zinc, nickel-plated