


E10628



Connection cable

VDOAH042ZDS00,3A03STGH030ZDS

Article no longer available - archive entry

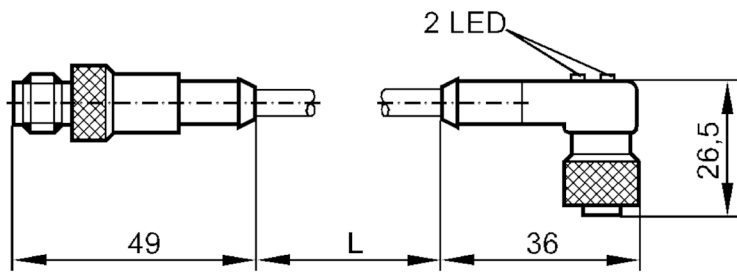

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	diecast zinc, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



E10628



Connection cable

VDOAH042ZDS00,3A03STGH030ZDS

Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

