


E10629



Connection cable


VDOAH042ZDS00,6A03STGH040ZDS

Article no longer available - archive entry

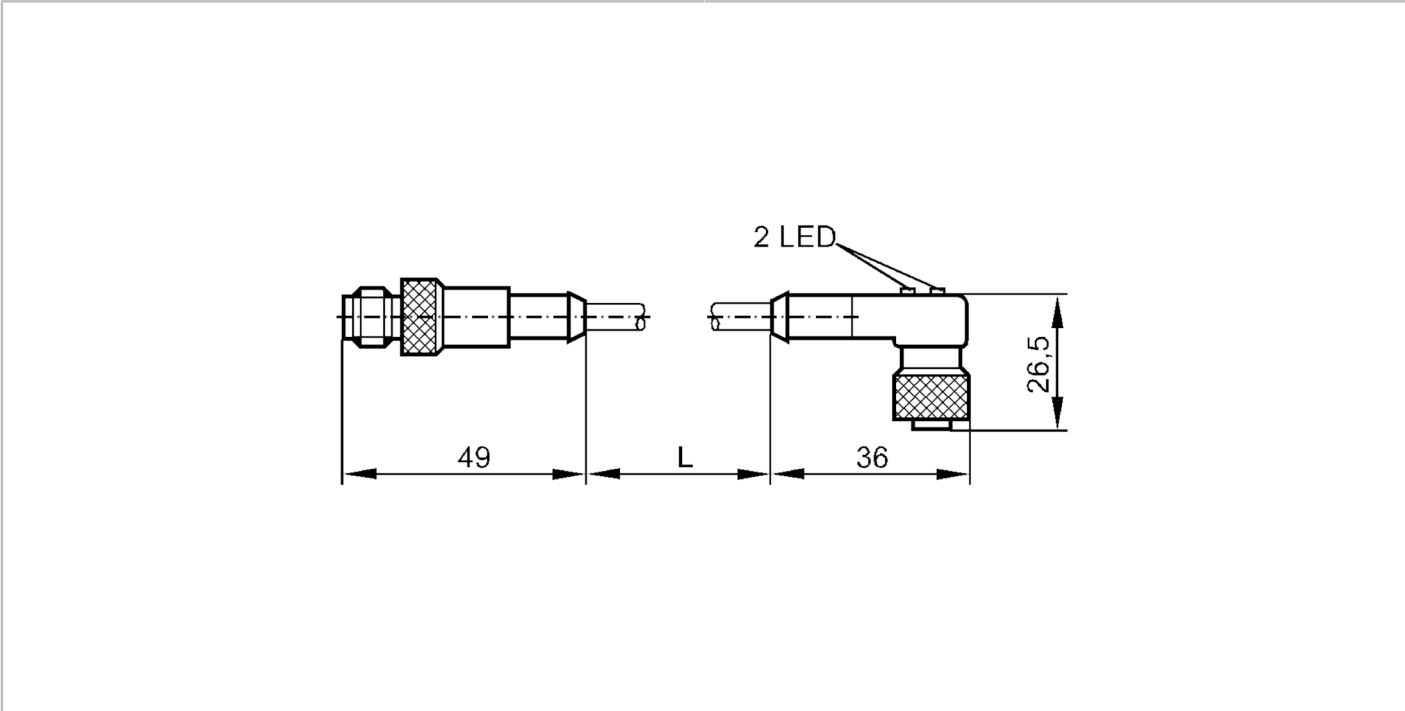

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

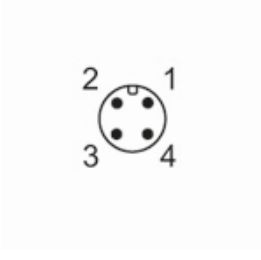

E10629



Connection cable

VDOAH042ZDS00,6A03STGH040ZDS

Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

