

E10644




Connecting cable with socket

ADOGH040VAS0005A03

Article no longer available - archive entry

Alternative articles: EVC002
When selecting an alternative article and accessories please note that technical data may differ!

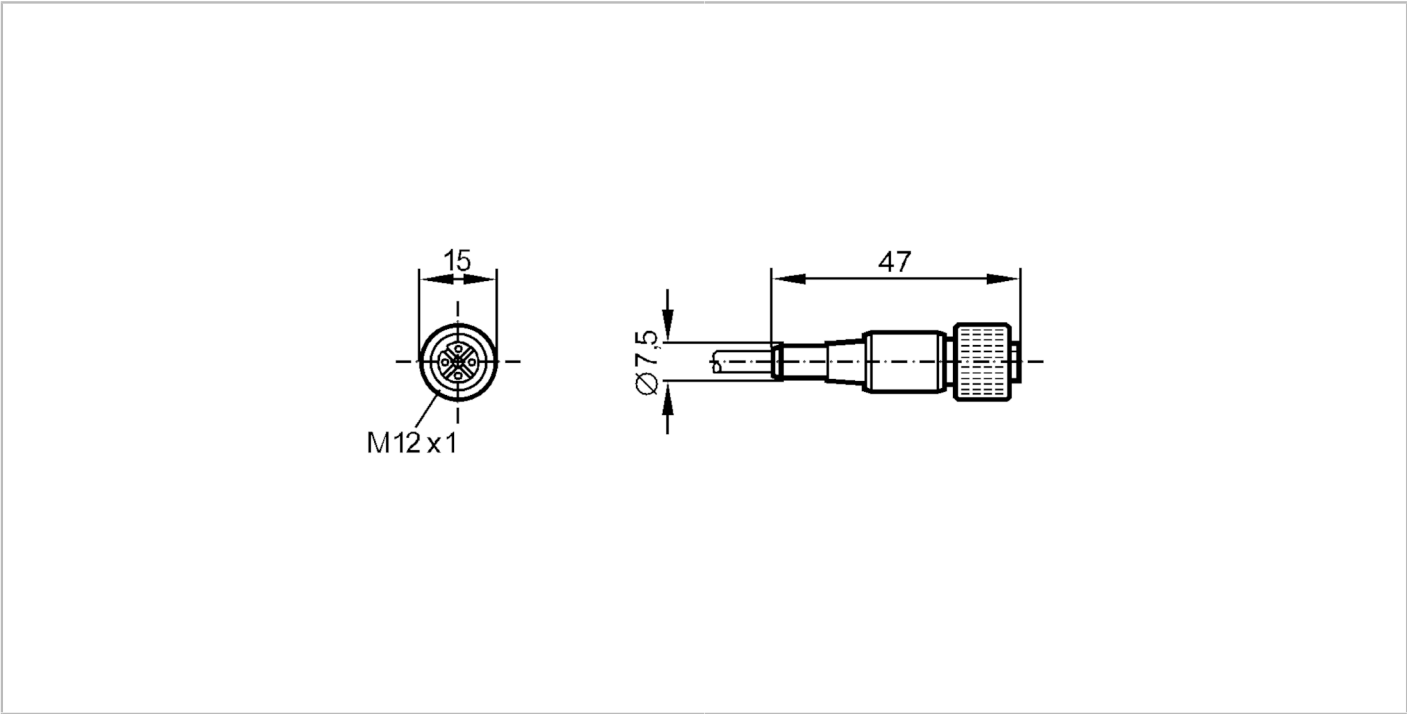

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 47
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel (1.4305 / 303)
Remarks		
Pack quantity		1 pcs.

E10644



Connecting cable with socket

ADOGH040VAS0005A03

Electrical connection


Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)



Connection

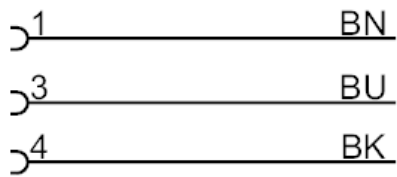

BK = Core colours :
BN = black
BU = brown
 blue