




Connection cable

VDOAF032MSS0001A03STGH030MSS

Article no longer available - archive entry

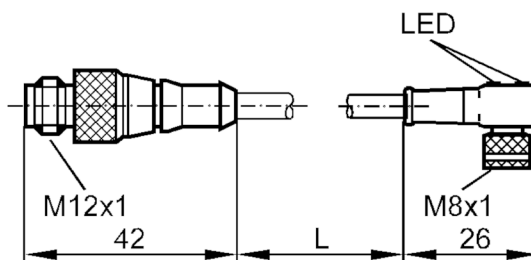

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Protection class	III
------------------	-----

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E10657



Connection cable

VDOAF032MSS0001A03STGH030MSS

Electrical connection

Cable: 1 m, PUR / PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection



Electrical connection - Buchse



Connection



Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated