


Splitter box

ZDO8H059MSS0000-00STAM190MSS

Article no longer available - archive entry

Alternative articles: EBC012

When selecting an alternative article and accessories please note that technical data may differ!

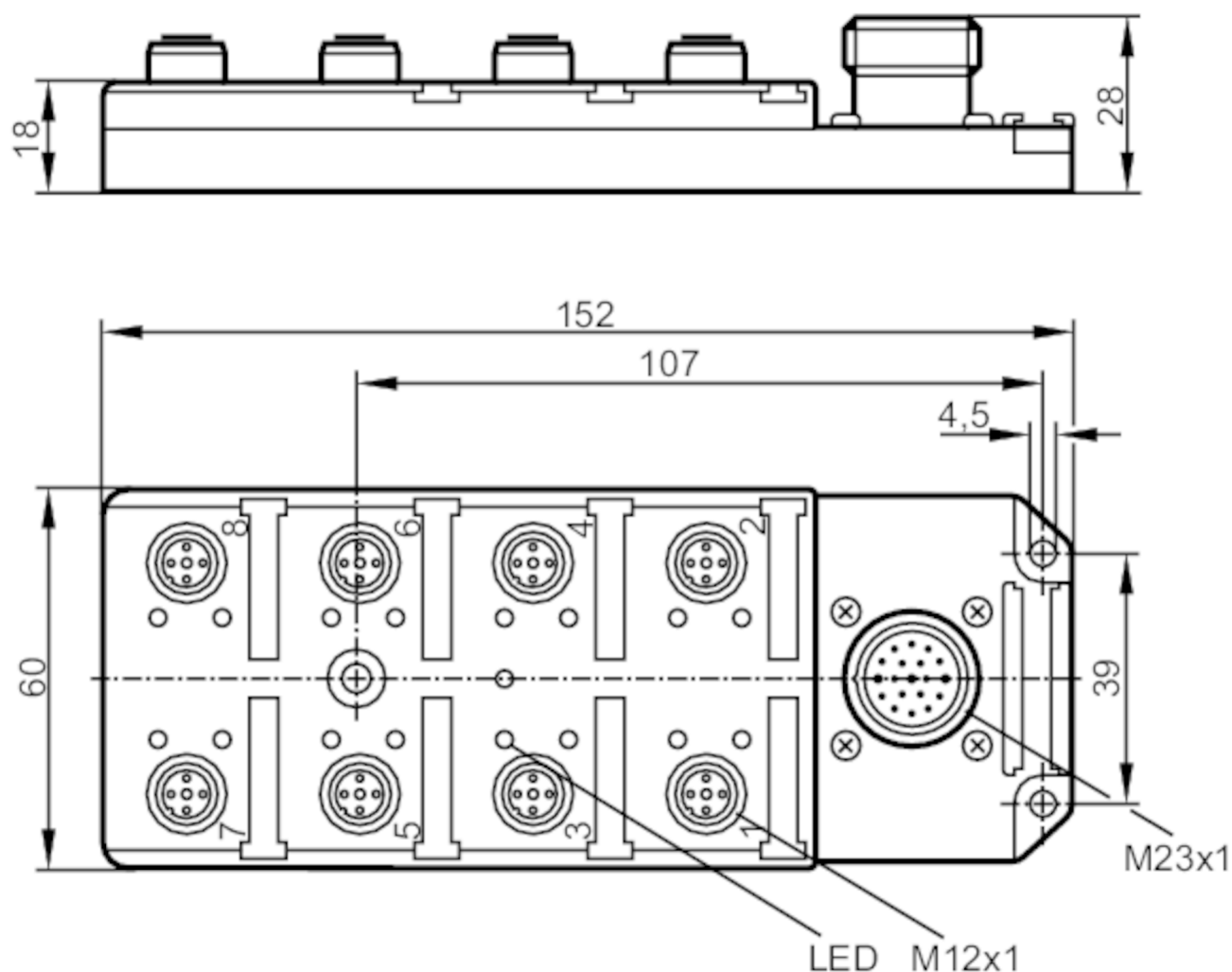

Application

Special feature

Free from silicone; Gold-plated contacts

Free from silicone

yes

Electrical data

Operating voltage

[V]

10...30 DC

Protection class

II

Max. current load per
module/slot

[A]

4

Max. current load total

[A]

10

Operating conditions

Ambient temperature

[°C]

-15...80

Protection

IP 67

E10659



Splitter box

ZDO8H059MSS0000-00STAM190MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 152
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		8
Connector type		M12
Displays / operating elements		
Display	switching status	16 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection - Connection		
Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm		


E10659



Splitter box

ZDO8H059MSS0000-00STAM190MSS

Connection

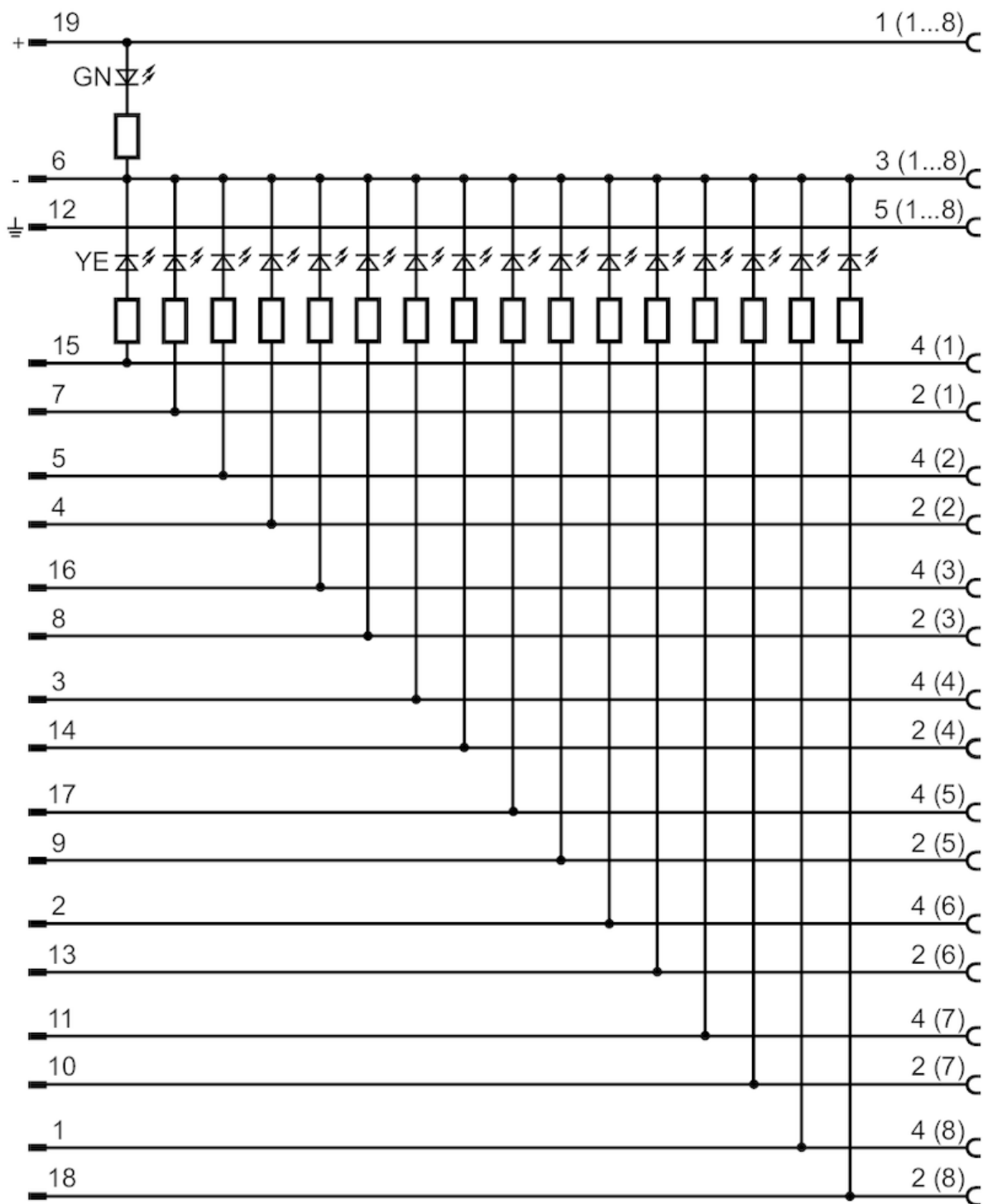

E10659



Splitter box

ZDO8H059MSS0000-00STAM190MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

