

E10665



Connecting cable with plug

ASTGH030MSS0002A03

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	10...55 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 2 m, PUR / PVC, orange, Ø 4.9 mm; 3 x 0.34 mm ² (42 x Ø 0.1 mm)		
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated




E10665



Connecting cable with plug

ASTGH030MSS0002A03

Connection

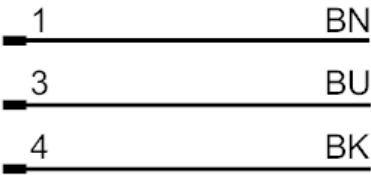

	Core colours :
BK =	black
BN =	brown
BU =	blue