


Jumper cable with valve plug

VVSAC041--S0003B03STGH040MSS

Article no longer available - archive entry

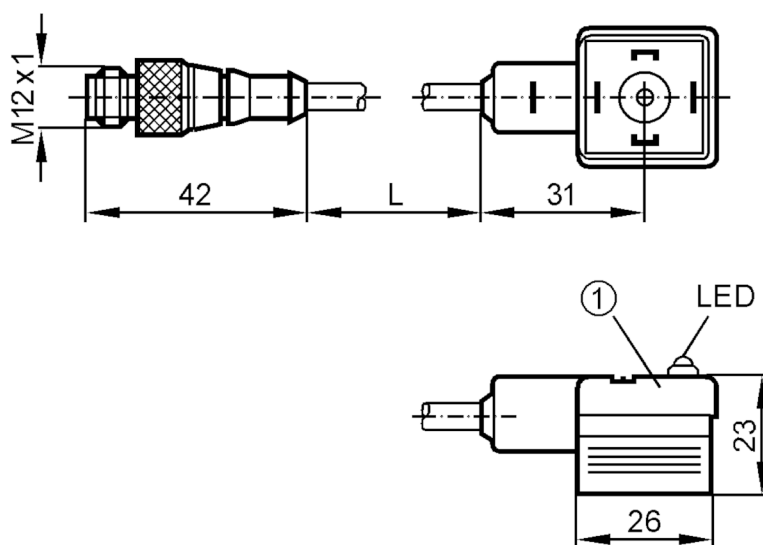

1 black

Electrical data

Operating voltage	[V]	< 24 AC/DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 65
------------	-------

Mechanical data

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10675




Jumper cable with valve plug

VVSAC041--S0003B03STGH040MSS

Electrical connection

Cable: 3 m, PUR; 3 x 0.34 mm²

Connection

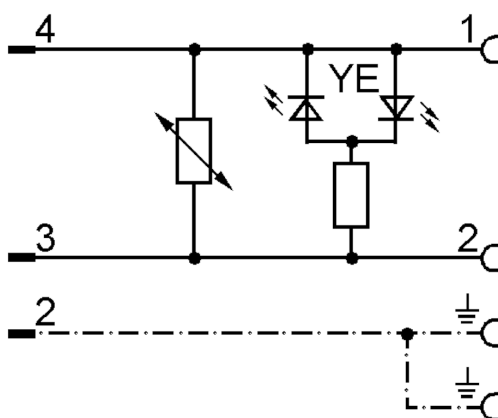

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

