

E10690




Connection cable

VDOAH040MSS0002B04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC018
When selecting an alternative article and accessories please note that technical data may differ!

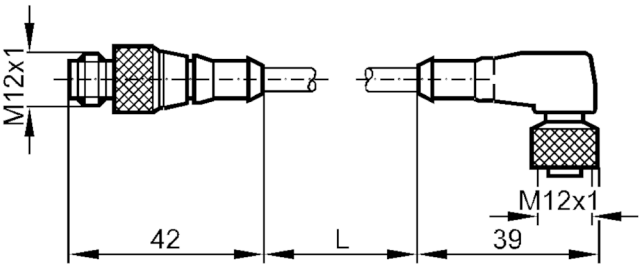

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E10690



Connection cable

VDOAH040MSS0002B04STGH040MSS

Electrical connection

Cable: 2 m, PUR, orange, Ø 5 mm; 4 x 0.25 mm² (128 x Ø 0.05 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

