


Connecting cable with socket

ADOAH040VAS0002A03

Article no longer available - archive entry

Alternative articles: EVC004

When selecting an alternative article and accessories please note that technical data may differ!

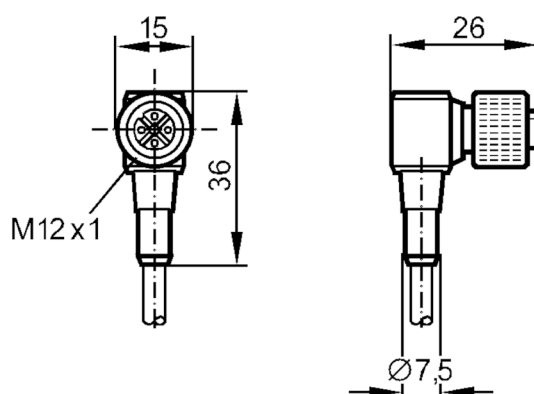

Electrical data

Operating voltage	[V]	< 60 AC/DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	stainless steel (1.4305 / 303)

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, black, $\varnothing$ 4.5 mm; 3 x 0.34 mm² (182 x $\varnothing$ 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)




E10727



Connecting cable with socket

ADOAH040VAS0002A03

Connection

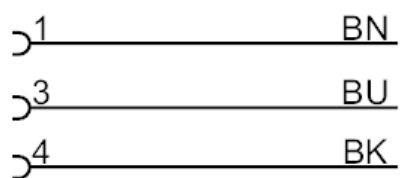

	Core colours :
BK =	black
BN =	brown
BU =	blue