

E10774




Wirable socket

SDOAH040PLSFKPG

Article no longer available - archive entry

Alternative articles: E11509 or E11658
When selecting an alternative article and accessories please note that technical data may differ!

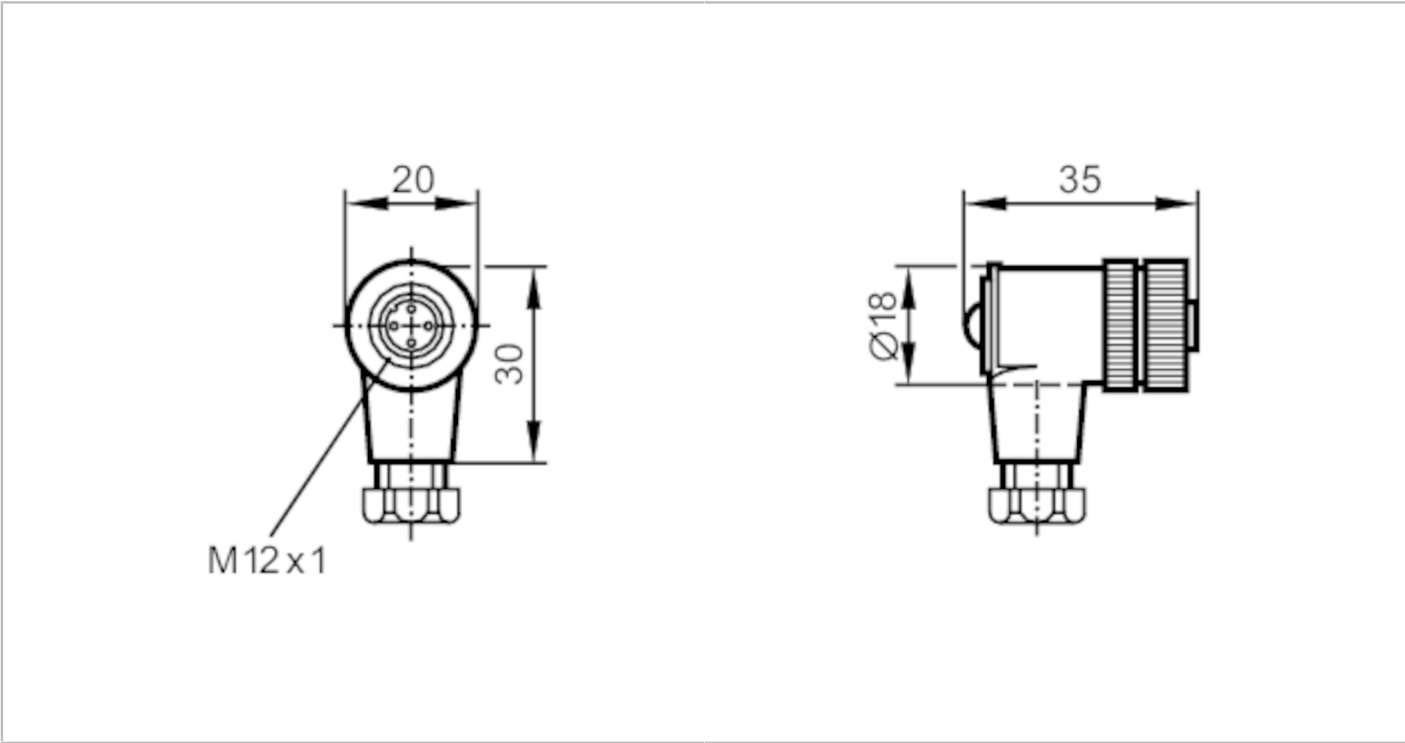

Electrical data		
Operating voltage	[V]	< 125 AC / < 150 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	35 x 20 x 30
Materials		PBT
Moulded-body material		PBT
Material nut		PA
Remarks		
Pack quantity		1 pcs.

E10774



Wirable socket

SDOAH040PLSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PBT; Locking: PA



Connection

