


Connecting cable with socket

ADOAF030MSS0005E03

Article no longer available - archive entry

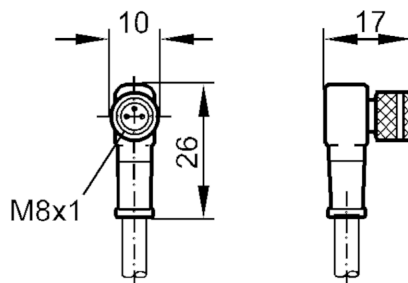

Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, orange, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated




E10787



Connecting cable with socket

ADOAF030MSS0005E03

Connection

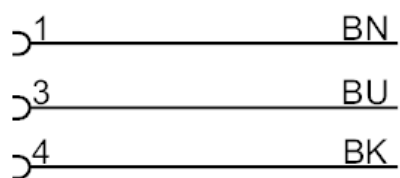

	Core colours :
BK =	black
BN =	brown
BU =	blue