


# E10788



## Wirable plug

SSTAA030MSSFKPG

Article no longer available - archive entry

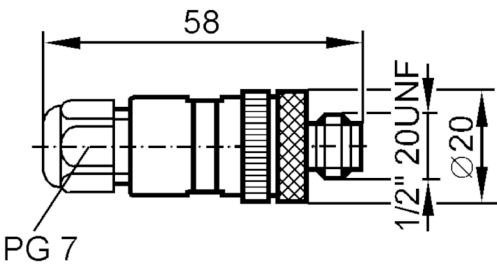

### Electrical data

|                   |     |          |
|-------------------|-----|----------|
| Operating voltage | [V] | < 250 AC |
|-------------------|-----|----------|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |      |                      |
|-----------------------|------|----------------------|
| Weight                | [g]  | 25                   |
| Dimensions            | [mm] | 20 x 20 x 58         |
| Materials             |      | PA                   |
| Moulded-body material |      | PA                   |
| Material nut          |      | brass, nickel-plated |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

### Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

### Electrical connection - plug

Connector: 1 x 1/2", straight; coding: C; Moulded body: PA; Locking: brass, nickel-plated



# E10788

## Wirable plug

SSTAA030MSSFKPG



### Connection

