


E10790




Wirable socket

SDOAH040MSSFKPG

Article no longer available - archive entry

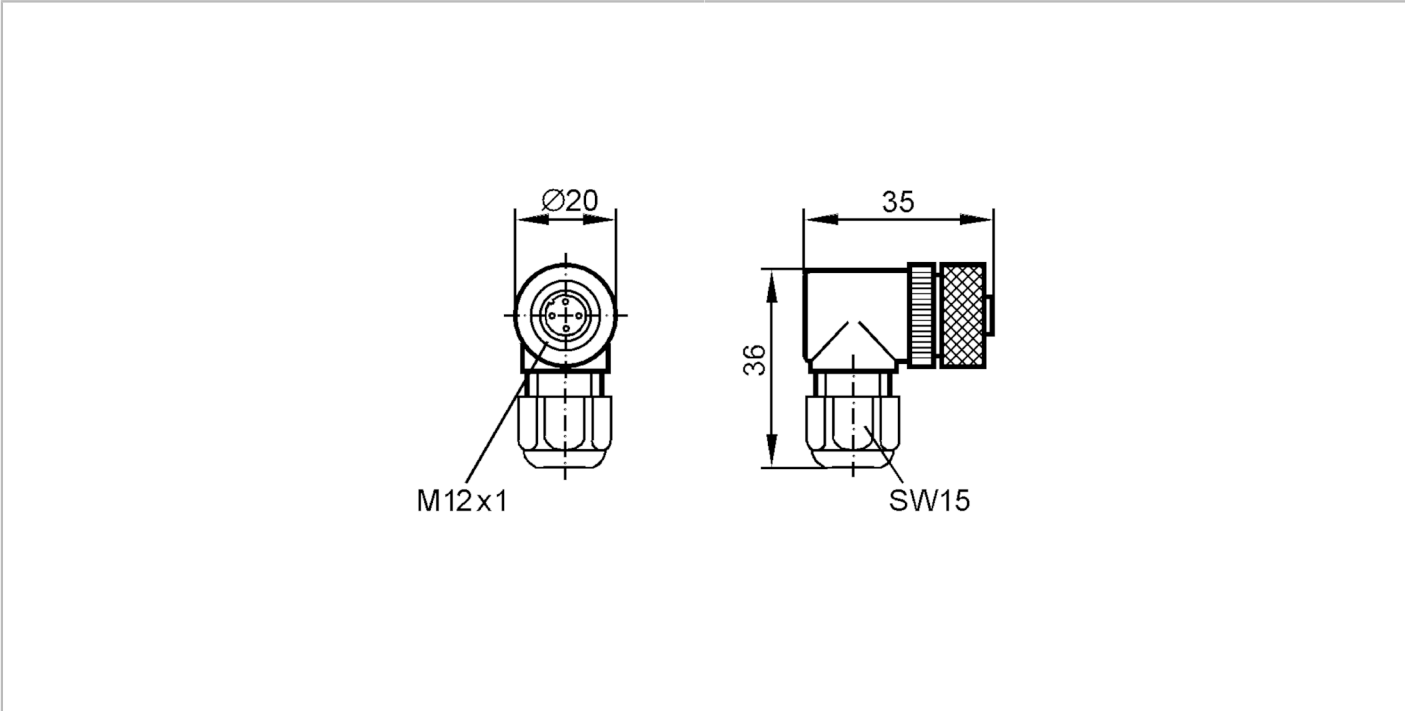

Electrical data		
Operating voltage	[V]	< 125 AC / < 150 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	36 x 20 x 35
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
terminals: ...0.75 mm²; Cable gland: PG 7		
Electrical connection - socket		
Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated		

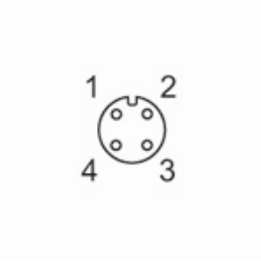

E10790

Wirable socket

SDOAH040MSSFKPG



Connection

