


# E10815



## Connection cable

VDOGH040MSS00,2A03STGX030

Article no longer available - archive entry

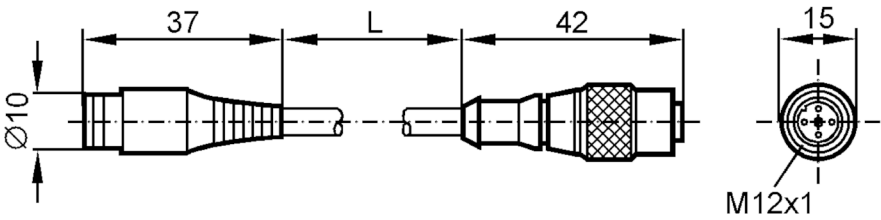

### Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...55 DC |
|-------------------|-----|------------|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...70 |
| Protection          |      | IP 65    |

### Mechanical data

|                       |                      |
|-----------------------|----------------------|
| Materials             | TPU                  |
| Moulded-body material | TPU                  |
| Material nut          | brass, nickel-plated |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug

Connector: 1 x Torson, straight; Moulded body: TPU; Locking: brass, nickel-plated



# E10815




## Connection cable

VDOGH040MSS00,2A03STGX030

### Electrical connection

Cable: 0.2 m, PUR / PVC

#### Connection

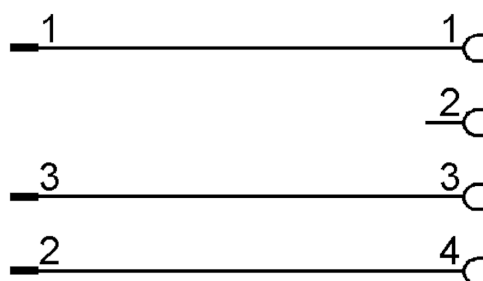

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

