


E10825



Jumper cable with valve plug

VVSAB030--N00,3E02STAH020VAN

Article no longer available - archive entry

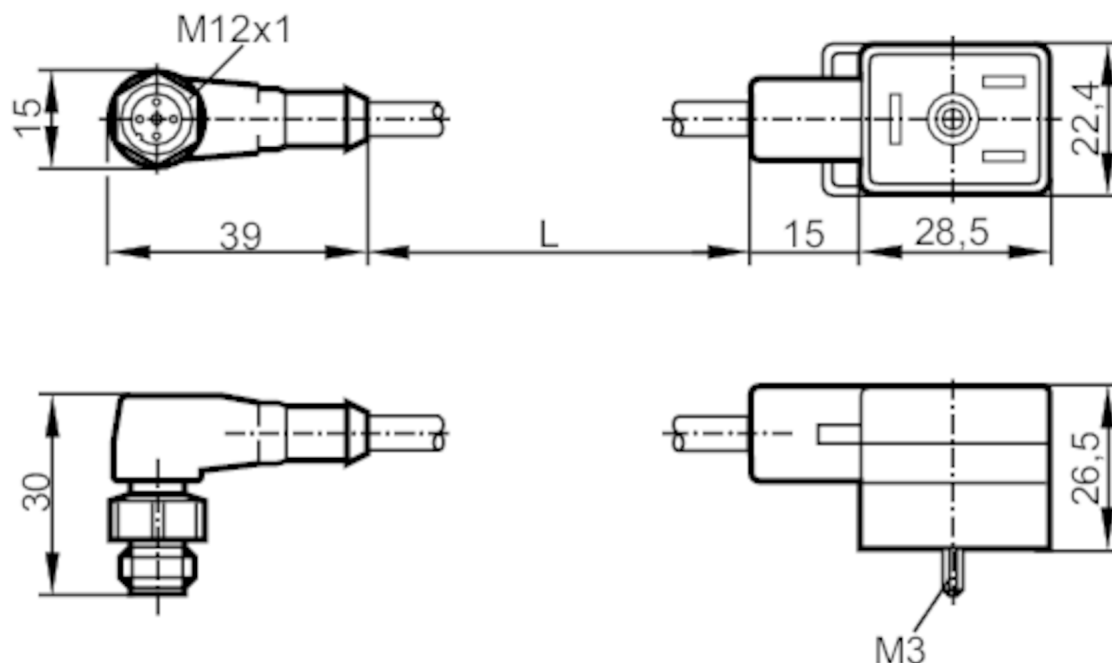

Application

Application

NAMUR

Electrical data

Operating voltage

[V]

< 15 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

15 x 30 x 39

Materials

TPU; PUR

Moulded-body material

TPU / PUR

Material nut

stainless steel (1.4404 / 316L)

Аксессуары

Items supplied

screw

panel for labelling

Remarks

Pack quantity

1 pcs.

E10825



Jumper cable with valve plug

VVSAB030--N00,3E02STAH020VAN

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)



Electrical connection

Cable: 0.3 m, PVC, blue, Ø 5 mm; 2 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

