




Connecting cable with socket

ADOGH040MSS0005F04

Article no longer available - archive entry

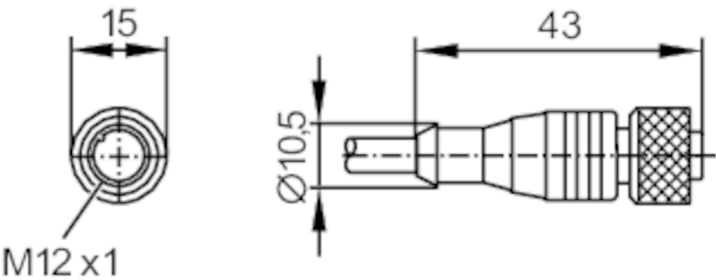

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)		
Electrical connection - socket		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated




E10829



Connecting cable with socket

ADOGH040MSS0005F04

Connection

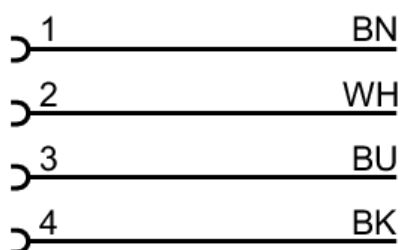

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white