


# E10844



## Jumper cable with valve plug

VVDAC041MSS00,3A03STAH030VAS

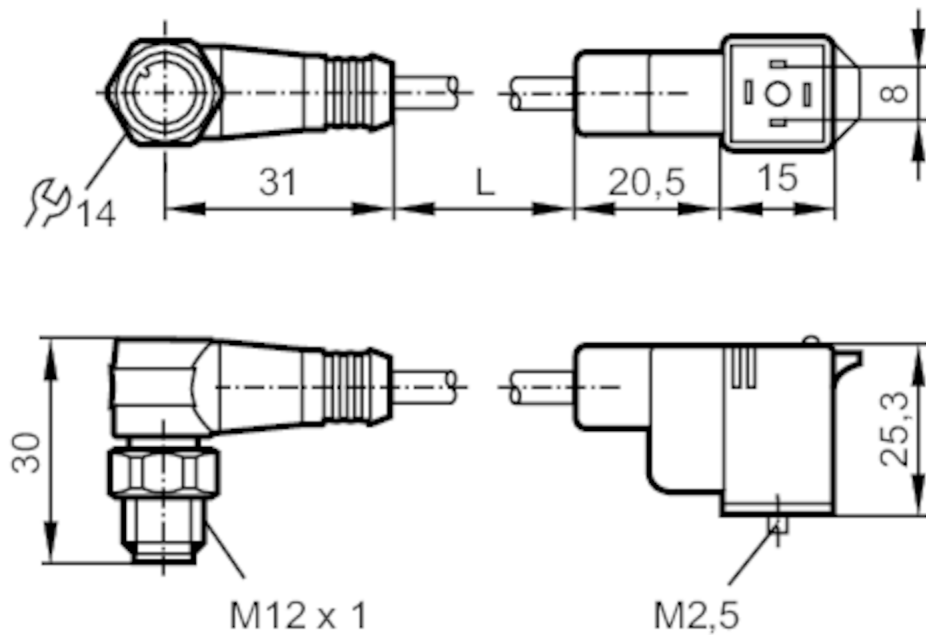

| Application                   |                                 |                 |
|-------------------------------|---------------------------------|-----------------|
| Special feature               | Halogen-free                    |                 |
| Electrical data               |                                 |                 |
| Operating voltage             | [V]                             | < 24 AC/DC      |
| Overtoltage protection        | yes; (VDR)                      |                 |
| Operating conditions          |                                 |                 |
| Ambient temperature           | [°C]                            | -25...90        |
| Protection                    | IP 67                           |                 |
| Mechanical data               |                                 |                 |
| Weight                        | [g]                             | 45.7            |
| Materials                     | TPU                             |                 |
| Moulded-body material         | TPU                             |                 |
| Material nut                  | stainless steel (1.4404 / 316L) |                 |
| Displays / operating elements |                                 |                 |
| Display                       | operation                       | 1 x LED, yellow |
| Аксессуары                    |                                 |                 |
| Items supplied                | screw                           |                 |
|                               | panel for labelling             |                 |
| Remarks                       |                                 |                 |
| Pack quantity                 | 1 pcs.                          |                 |

# E10844

 


## Jumper cable with valve plug

VVDAC041MSS00,3A03STAH030VAS

### Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm<sup>2</sup> (16 x Ø 0.2 mm )

### Connection

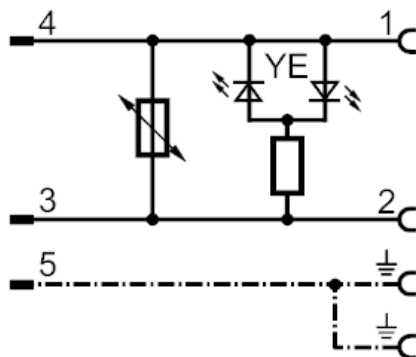

### Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: TPU; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm

