


E10845



Jumper cable with valve plug

VVDAC041MSS00,6A03STAH030VAS

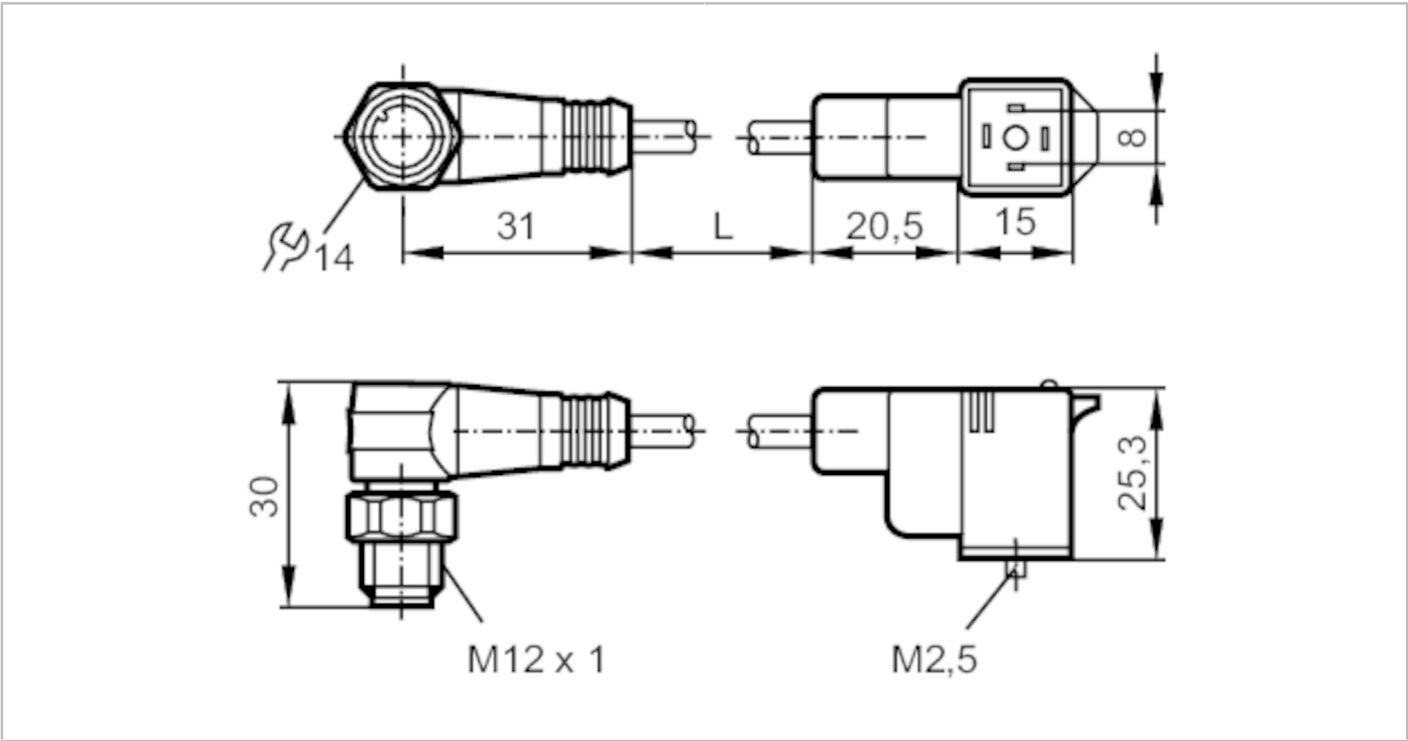

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overtoltage protection	yes; (VDR)	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Weight	[g]	58.6
Materials	TPU	
Moulded-body material	TPU	
Material nut	stainless steel (1.4404 / 316L)	
Displays / operating elements		
Display	operation	1 x LED, yellow
Аксессуары		
Items supplied	screw	
	panel for labelling	
Remarks		
Pack quantity	1 pcs.	

E10845



Jumper cable with valve plug

VVDAC041MSS00,6A03STAH030VAS

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection



Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: TPU; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm

