


E10846



Jumper cable with valve plug

VVDAC040--N00,3E02STAH020VAN

Article no longer available - archive entry

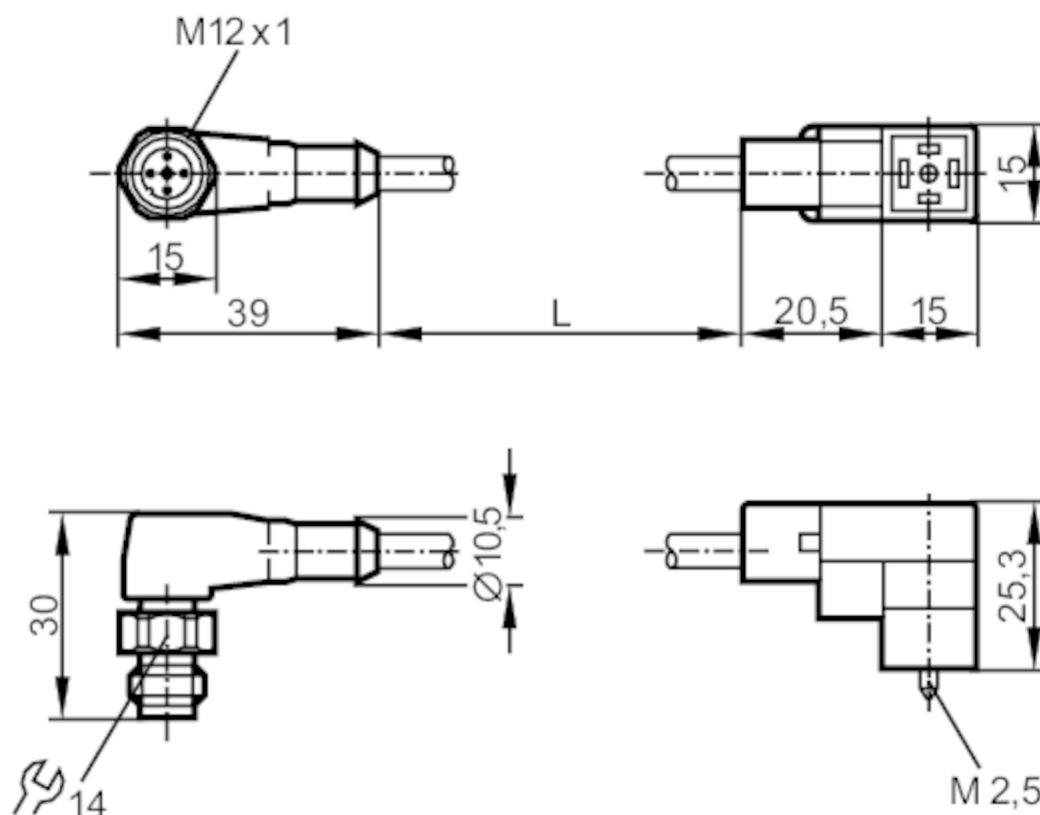

Application

Application	NAMUR
-------------	-------

Electrical data

Operating voltage	[V]	< 15 DC
-------------------	-----	---------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	30 x 15 x 39
------------	------	--------------

Materials	TPU; PUR
-----------	----------

Moulded-body material	TPU / PUR
-----------------------	-----------

Material nut	stainless steel (1.4404 / 316L)
--------------	---------------------------------

Аксесуари

Items supplied	screw
----------------	-------

panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E10846



Jumper cable with valve plug

VVDAC040--N00,3E02STAH020VAN

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)



Electrical connection

Cable: 0.3 m, PVC, blue, Ø 5 mm; 2 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

