


E10847



Jumper cable with valve plug

VVDAC040--N00,6E02STAH020VAN

Article no longer available - archive entry

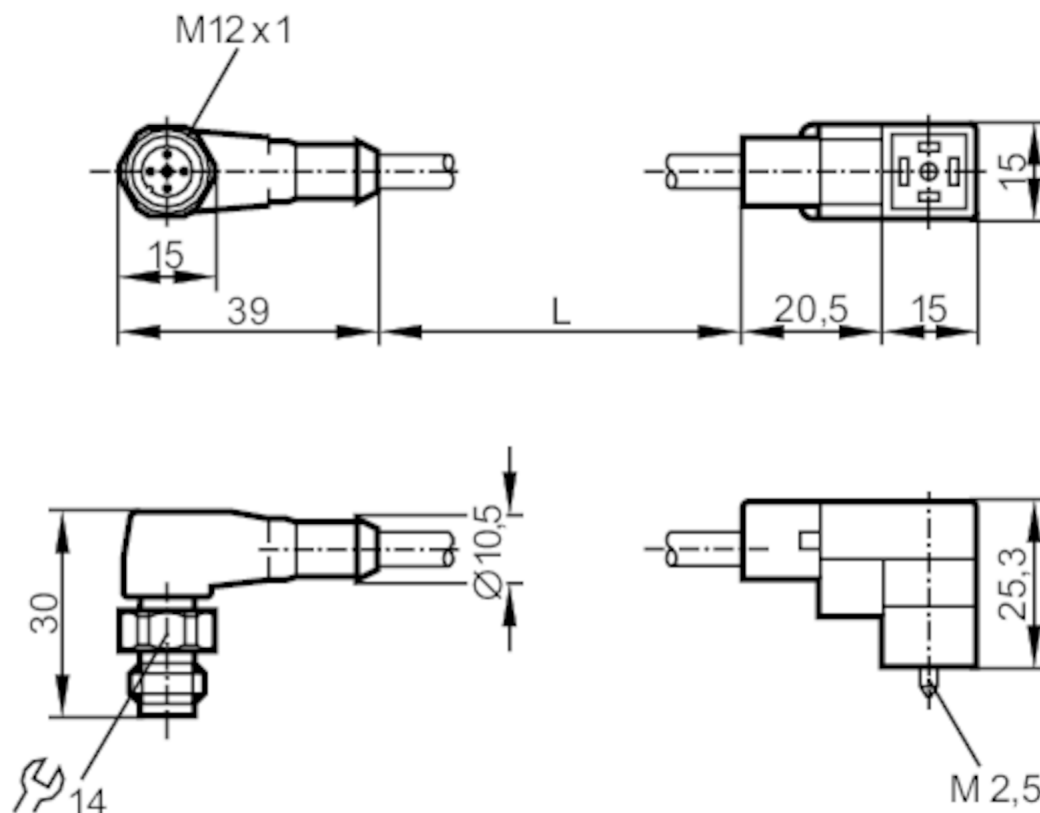

Application

Application NAMUR

Electrical data

Operating voltage [V] < 15 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 30 x 15 x 39

Materials TPU; PUR

Moulded-body material TPU / PUR

Material nut stainless steel (1.4404 / 316L)

Аксессуары

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.

E10847



Jumper cable with valve plug

VVDAC040--N00,6E02STAH020VAN

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)



Electrical connection

Cable: 0.6 m, PUR / PVC, blue, Ø 5 mm; 2 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: TPU / PUR; Locking: stainless steel (1.4404 / 316L)

