


E10852



Connecting cable with socket

ADOGA040VAS0005E04

Article no longer available - archive entry

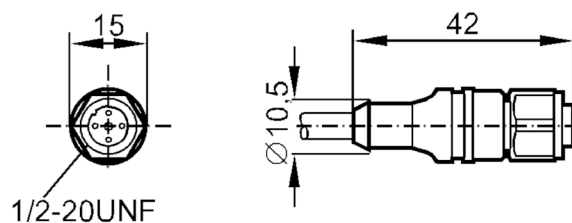

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 42
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E10852



Connecting cable with socket


ADOGA040VAS0005E04

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated

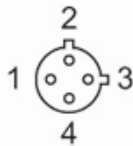

Connection



BK = Core colours :
BN = black
BU = brown
WH = blue
BK = white