




Connecting cable with socket

ADOAH043MSS0002H04

Article no longer available - archive entry

Alternative articles: EVC007
When selecting an alternative article and accessories please note that technical data may differ!

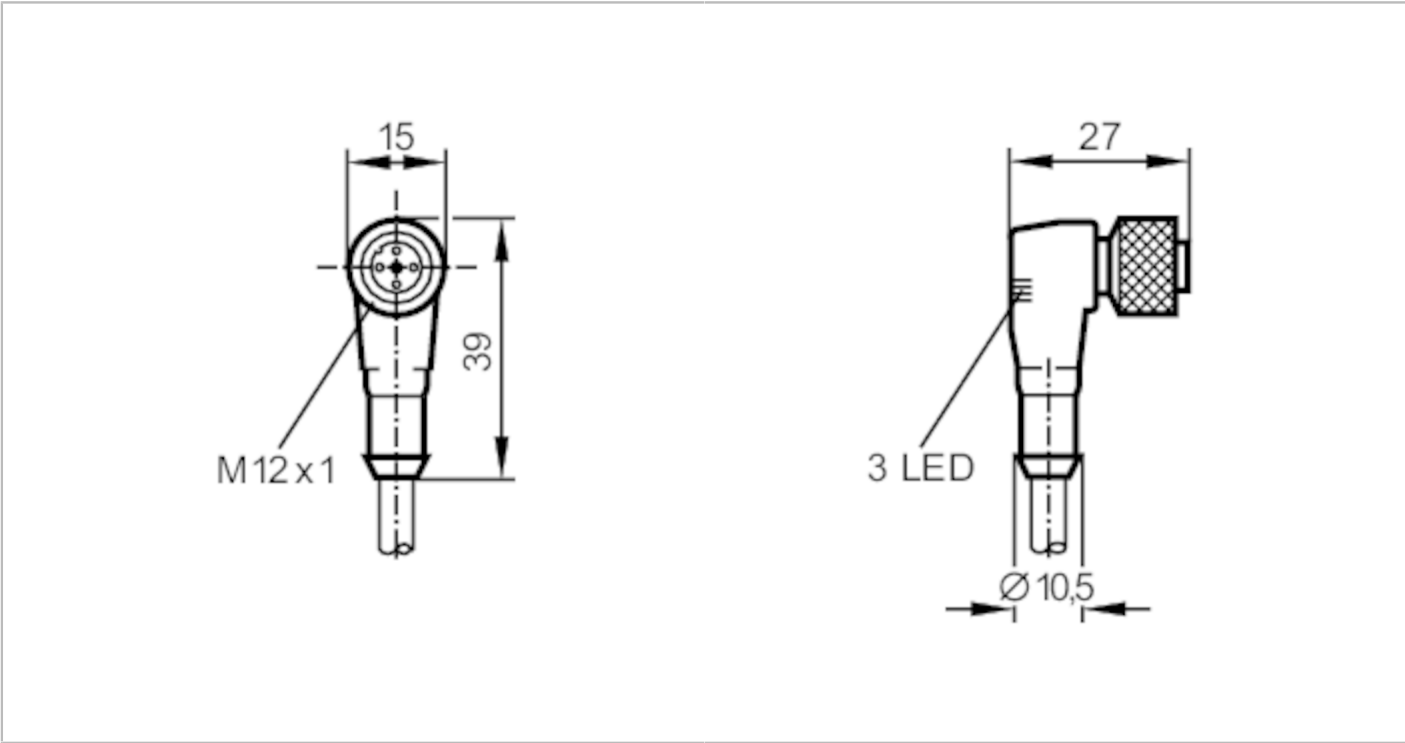

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design	PNP	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials	TPU transparent	
Moulded-body material	TPU, transparent	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	2 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity	1 pcs.	

E10854



Connecting cable with socket

ADOAH043MSS0002H04

Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; 4 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated



Connection



BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white