




Connecting cable with socket

ADOAF040MSS0005E04

Article no longer available - archive entry

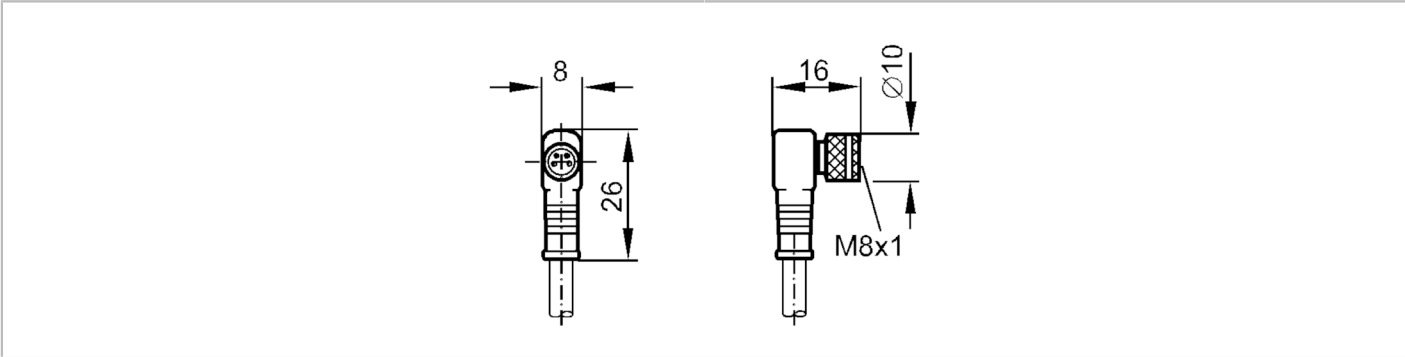

Electrical data

|                   |     |                   |
|-------------------|-----|-------------------|
| Operating voltage | [V] | < 60 AC / < 75 DC |
| Protection class  |     | III               |

Operating conditions

|                     |      |                        |
|---------------------|------|------------------------|
| Ambient temperature | [°C] | -25...90               |
| Protection          |      | IP 67; (if screwed on) |

Mechanical data

|                       |      |                      |
|-----------------------|------|----------------------|
| Dimensions            | [mm] | 16 x 8 x 26          |
| Materials             |      | TPU                  |
| Moulded-body material |      | TPU                  |
| Material nut          |      | brass, nickel-plated |

Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm²

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated




# E10862



## Connecting cable with socket

ADOAF040MSS0005E04

### Connection

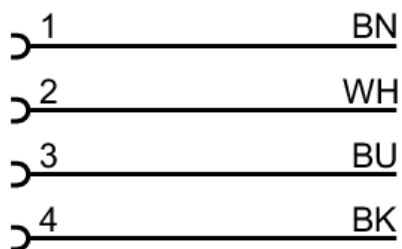

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| WH = | white          |