


E10867



Connecting cable with socket

ADOGH030MSS0002E03

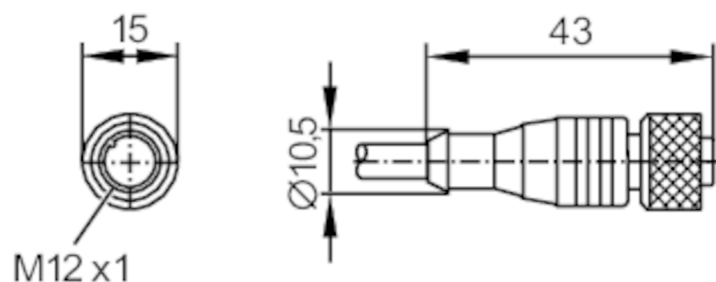

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Weight [g] 87.5

Dimensions [mm] 15 x 15 x 43

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

E10867



Connecting cable with socket

ADOGH030MSS0002E03

Electrical connection


Cable: 2 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: C; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

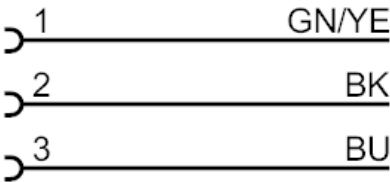

BK = Core colours :
BU = black
GN/YE = blue
 green/yellow