


E10868



Connecting cable with socket

ADOGH030MSS0005E03

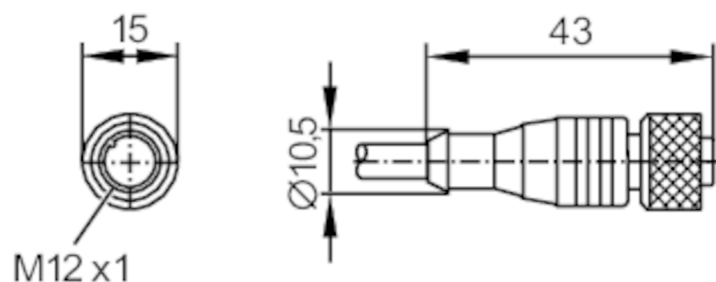

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	198.3
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10868



Connecting cable with socket

ADOGH030MSS0005E03

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: C; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

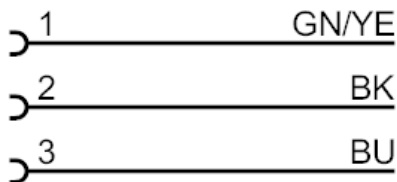

BK = Core colours :
BU = black
GN/YE = blue
green/yellow