

E10878




Wirable plug

SSTGH030MSSFKPG

Article no longer available - archive entry

Alternative articles: E70154
When selecting an alternative article and accessories please note that technical data may differ!

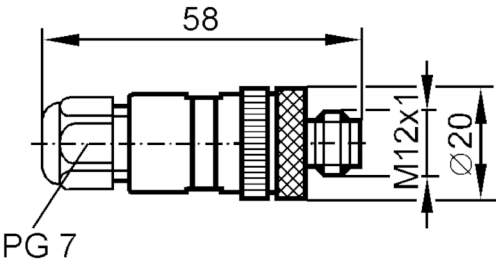

Electrical data		
Operating voltage	[V]	< 125 AC / < 150 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	20 x 20 x 58
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10878



Wirable plug

SSTGH030MSSFKPG

Electrical connection

terminals: ...0.75 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated



Connection

