

E10884




Connection cable

VDOGH040MSS0005I04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVW028
When selecting an alternative article and accessories please note that technical data may differ!

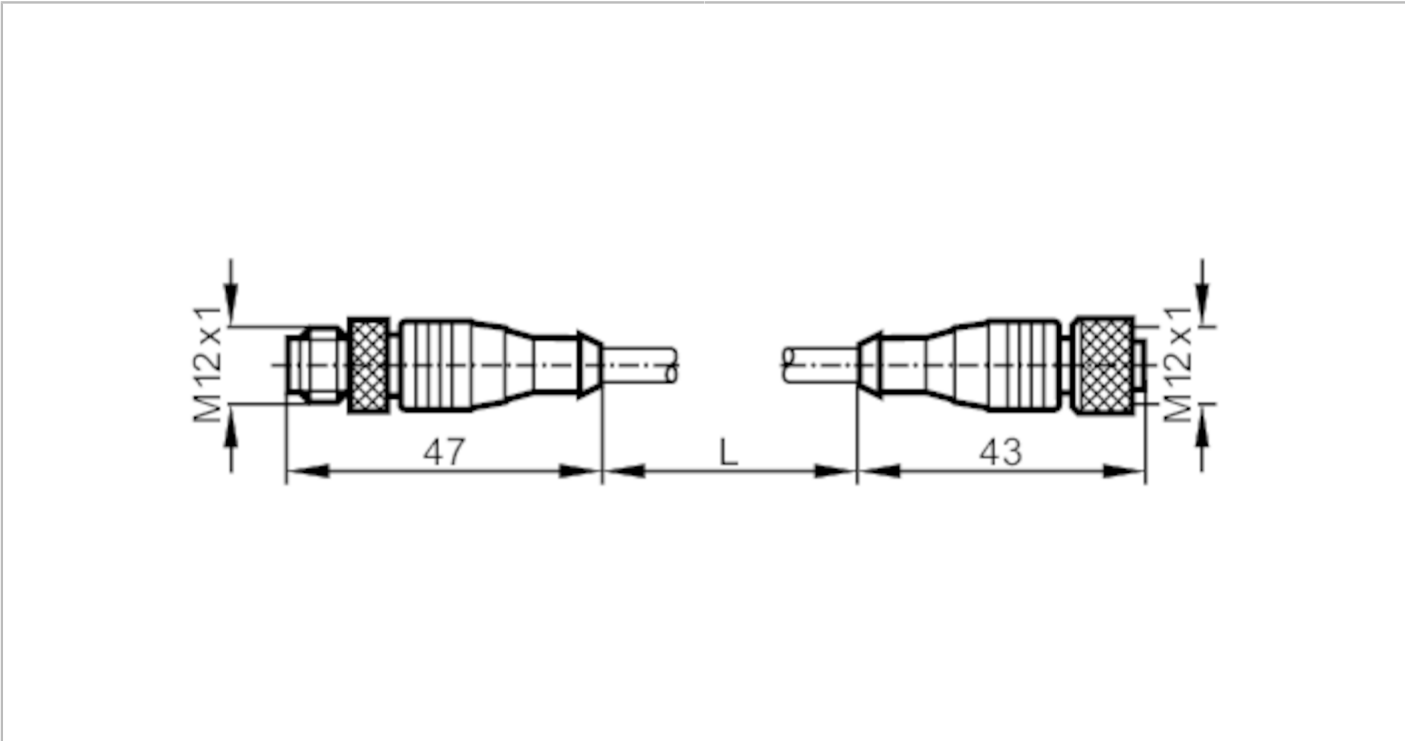

Application	
Special feature	Halogen-free; Gold-plated contacts
Electrical data	
Operating voltage	[V] < 250 AC / < 300 DC
Operating conditions	
Ambient temperature	[°C] -25...90
Protection	IP 67
Mechanical data	
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E10884



Connection cable

VDOGH040MSS0005I04STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

