

E10885




Splitter box

ZDO4H050MSS0000-00STAK190MSS

Article no longer available - archive entry

Alternative articles: E11728

When selecting an alternative article and accessories please note that technical data may differ!

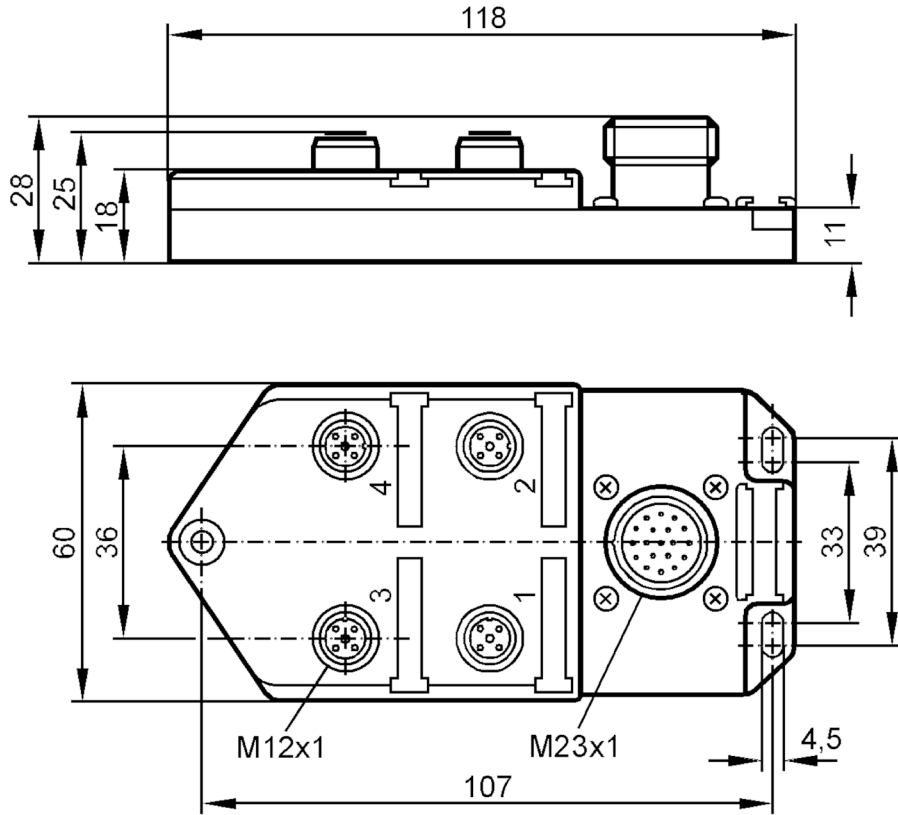

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...55 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Dimensions [mm]	28 x 60 x 118
Number of ports splitter box	4
Connector type	M12

Remarks

Pack quantity	1 pcs.
---------------	--------

E10885




Splitter box

ZDO4H050MSS0000-00STAK190MSS

Electrical connection - Connection

Connector: 1 x M23; Contacts: gold-plated; Tightening torque: 0.5 Nm

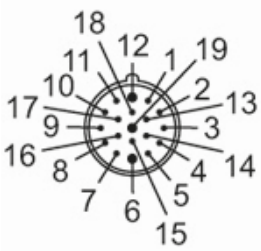

Connection

+	19	1 (1...4)
-	6	3 (1...4)
≡	12	5 (1...4)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)

Electrical connection - slot

Connector: 4 x M12; coding: A; Contacts: gold-plated; Tightening torque: 0.5 Nm

