

E10909




Connecting cable with socket

ADOAH040SCS0002I04

Article no longer available - archive entry

Alternative articles: EVW004
When selecting an alternative article and accessories please note that technical data may differ!

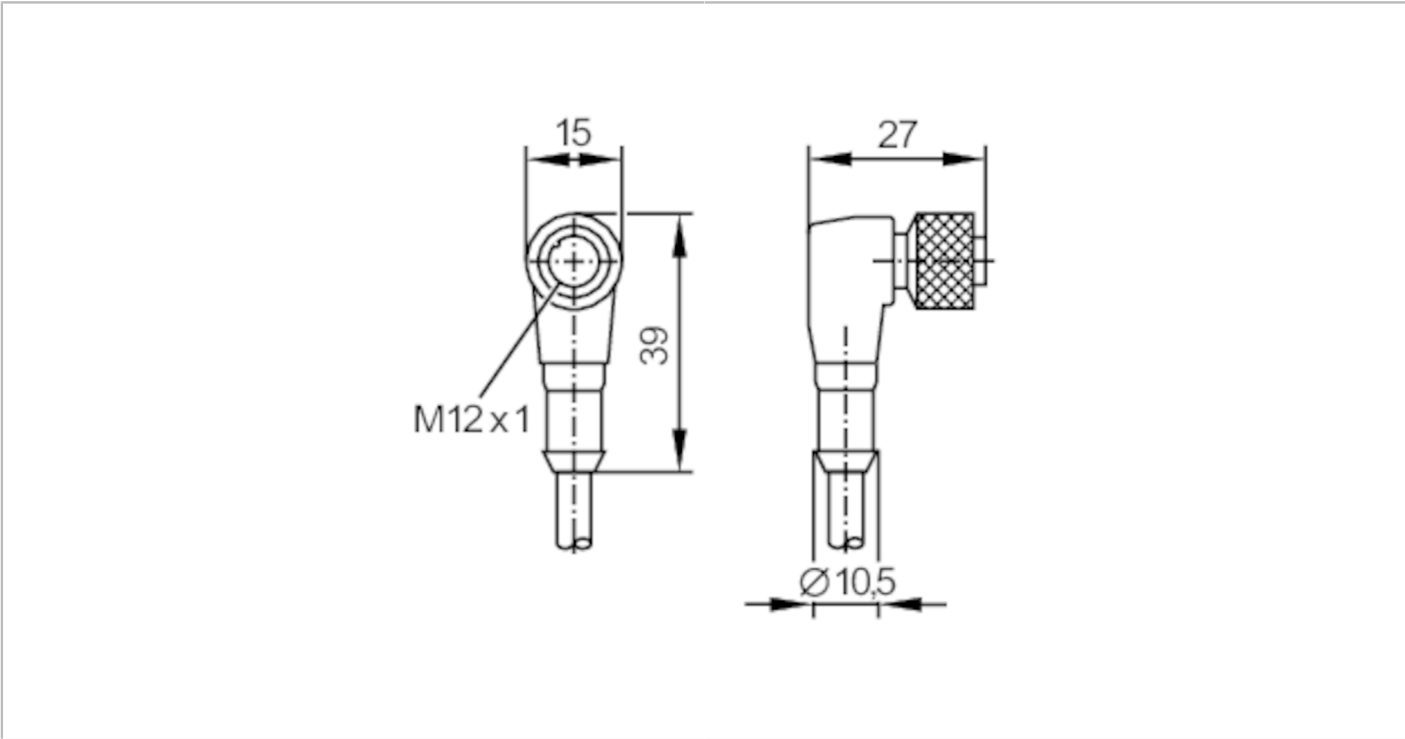

Application		
Special feature		Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter
Remarks		
Pack quantity		1 pcs.

E10909



Connecting cable with socket


ADOAH040SCS0002I04

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm

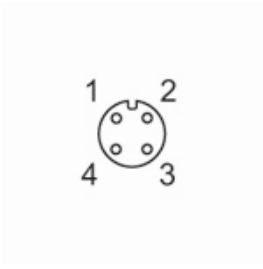

Connection

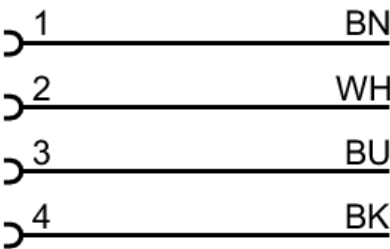

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white