




Connecting cable with socket

ADOAH043SCS0002I04

Article no longer available - archive entry

Alternative articles: EVW007
When selecting an alternative article and accessories please note that technical data may differ!

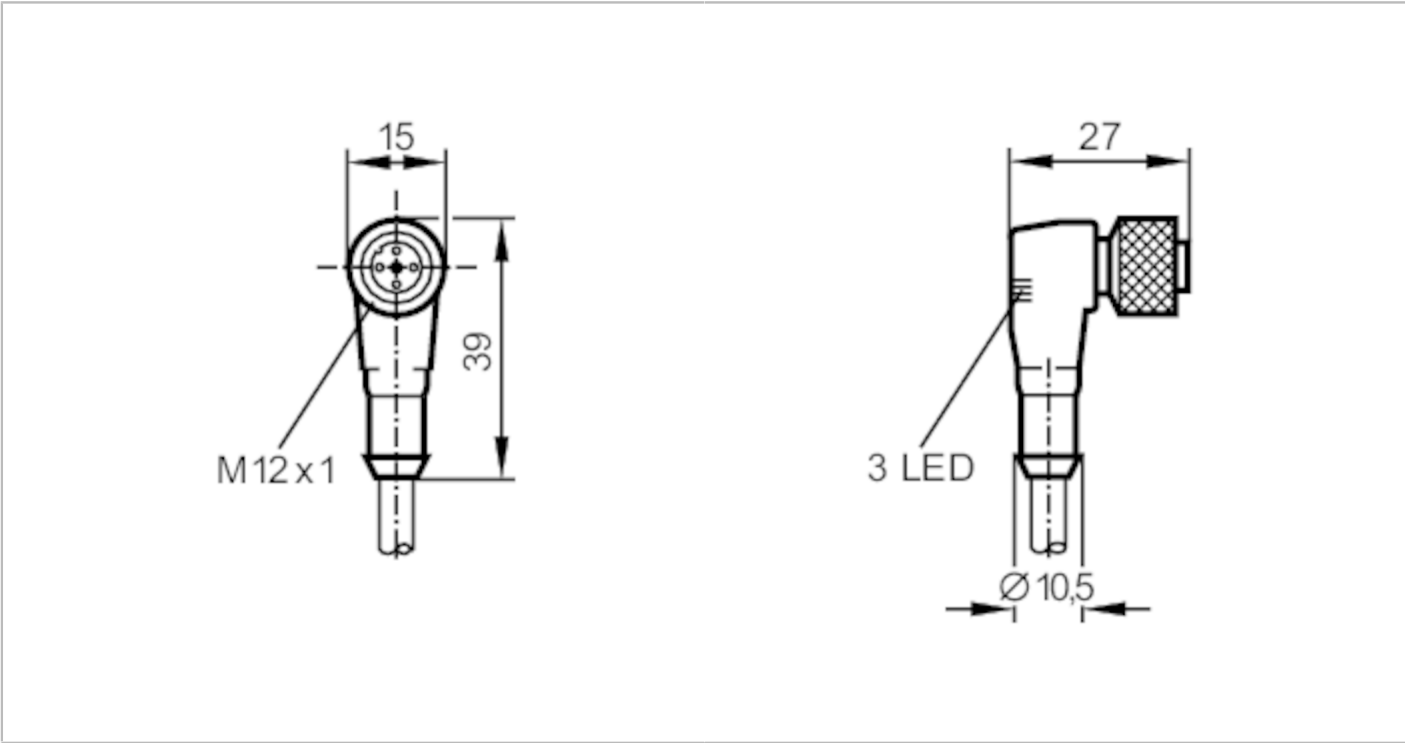

Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Max. current load total	[A]	4
Outputs		
Electrical design	PNP	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 68	
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials	TPU transparent	
Moulded-body material	TPU, transparent	
Material nut	brass, anti-spatter	
Displays / operating elements		
Display	switching status	2 x LED, yellow
	operation	1 x LED, green

E10912



Connecting cable with socket

ADOAH043SCS0002I04

Remarks

 
Pack quantity 1 pcs.

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

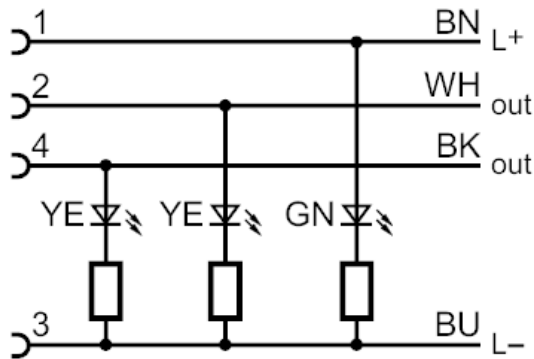

BK = black
BN = brown
BU = blue
WH = white

Core colours :