


Connecting cable with socket

ADOAH043SCS0010I04

Article no longer available - archive entry

Alternative articles: EVW009

When selecting an alternative article and accessories please note that technical data may differ!

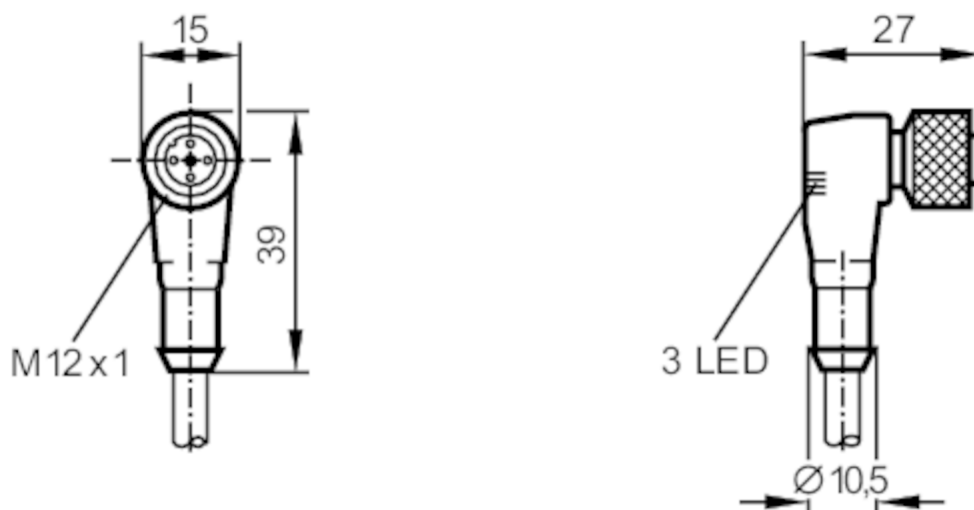

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	4

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Materials		TPU transparent
Moulded-body material		TPU, transparent
Material nut		brass, anti-spatter

Displays / operating elements

Display	switching status	2 x LED, yellow
	operation	1 x LED, green

E10914



Connecting cable with socket

ADOAH043SCS0010I04

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection


Cable: 10 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm²

Electrical connection - socket

 Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, anti-spatter; Contacts: gold-plated;
Tightening torque: 0.5 Nm



Connection

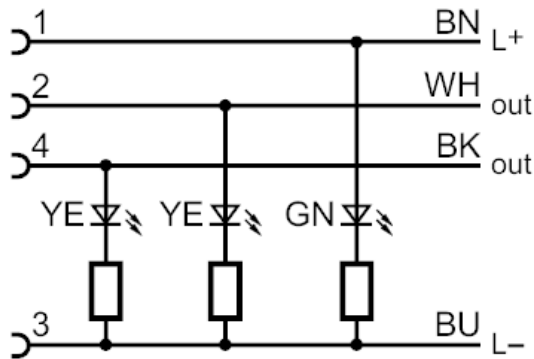

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white