


E10928



Connection cable

VDOGF030MSS00,6H03STGF030MSS

Article no longer available - archive entry

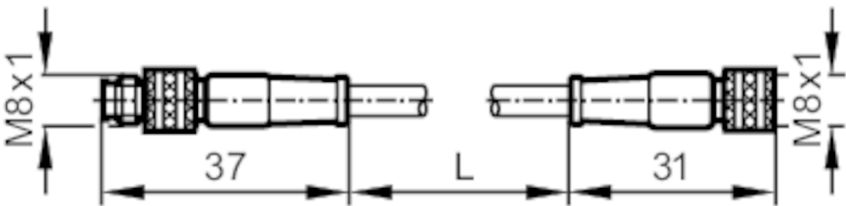

Application	
Special feature	Halogen-free
Electrical data	
Operating voltage [V]	10...55 DC
Protection class	III
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10928




Connection cable

VDOGF030MSS00,6H03STGF030MSS

Electrical connection

Cable: 0.6 m, Halogen-free; 3 x 0.34 mm²

Connection

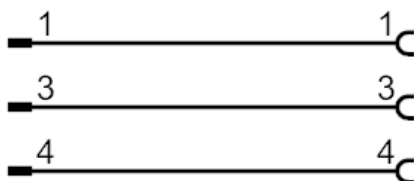

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

