


Connection cable

VDOG F030MSS0002H03STGF030MSS

Article no longer available - archive entry

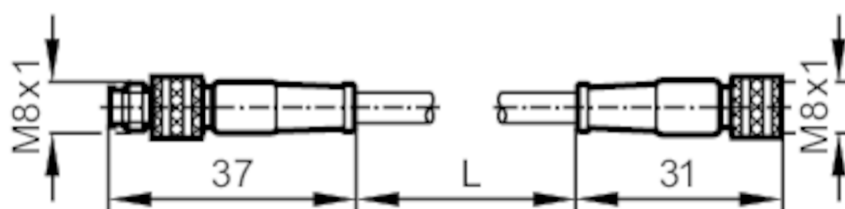

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...55 DC

Protection class

III

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10930




Connection cable

VDOGF030MSS0002H03STGF030MSS

Electrical connection

Cable: 2 m, Halogen-free; 3 x 0.34 mm²

Connection

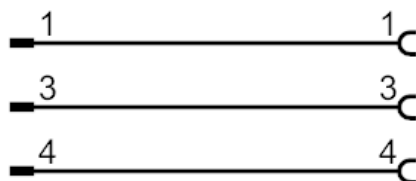

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

