




Connection cable

VDOAH040MSS0002H03STGF030MSS

Article no longer available - archive entry

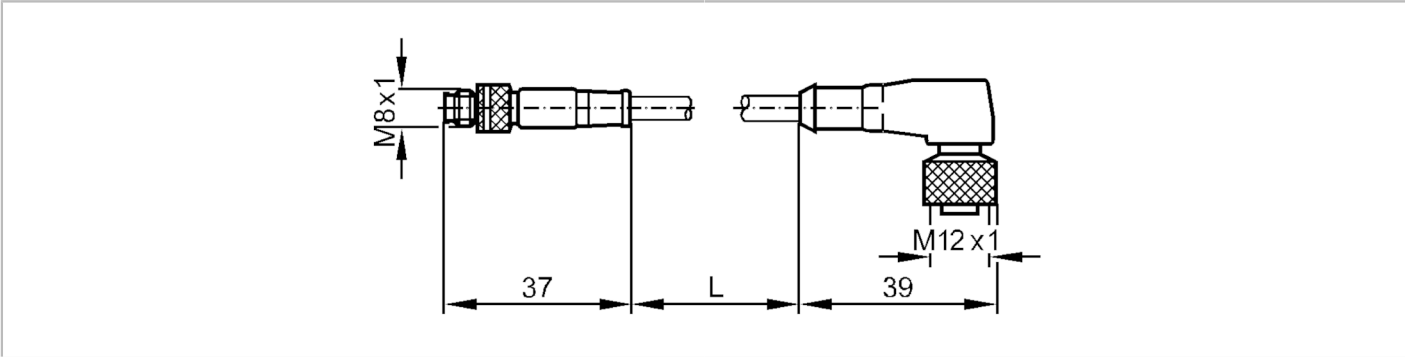

Application

|                 |              |
|-----------------|--------------|
| Special feature | Halogen-free |
|-----------------|--------------|

Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
| Protection class  |     | III        |

Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

Mechanical data


|                       |                      |
|-----------------------|----------------------|
| Materials             | TPU                  |
| Moulded-body material | TPU                  |
| Material nut          | brass, nickel-plated |

Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

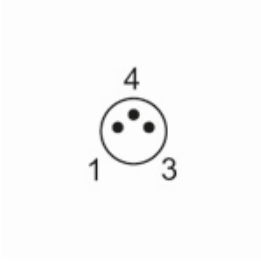

# E10939



## Connection cable

VDOAH040MSS0002H03STGF030MSS

### Electrical connection

Cable: 2 m, Halogen-free; 3 x 0.34 mm<sup>2</sup>

#### Connection



### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

