

E10940




Connection cable

VDOAH042MSS00,6H03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11347

When selecting an alternative article and accessories please note that technical data may differ!

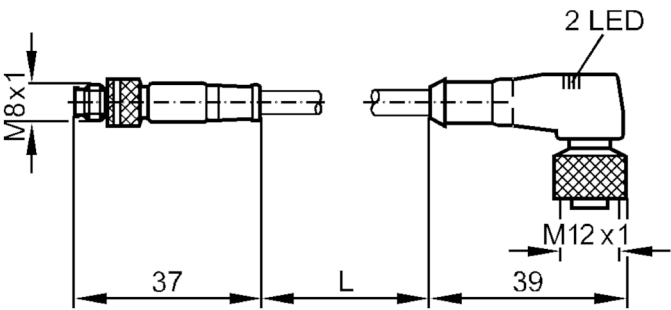

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10940




Connection cable

VDOAH042MSS00,6H03STGF030MSS

Electrical connection

Cable: 0.6 m, TPU, Halogen-free; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

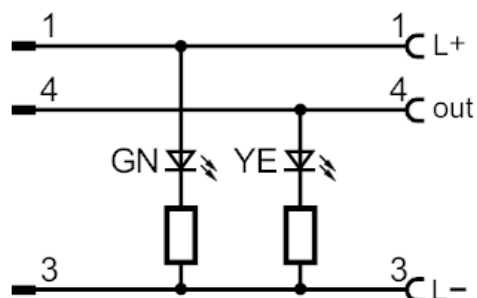

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

