




Connecting cable with socket

ADOGF030VAS0010A03

Article no longer available - archive entry

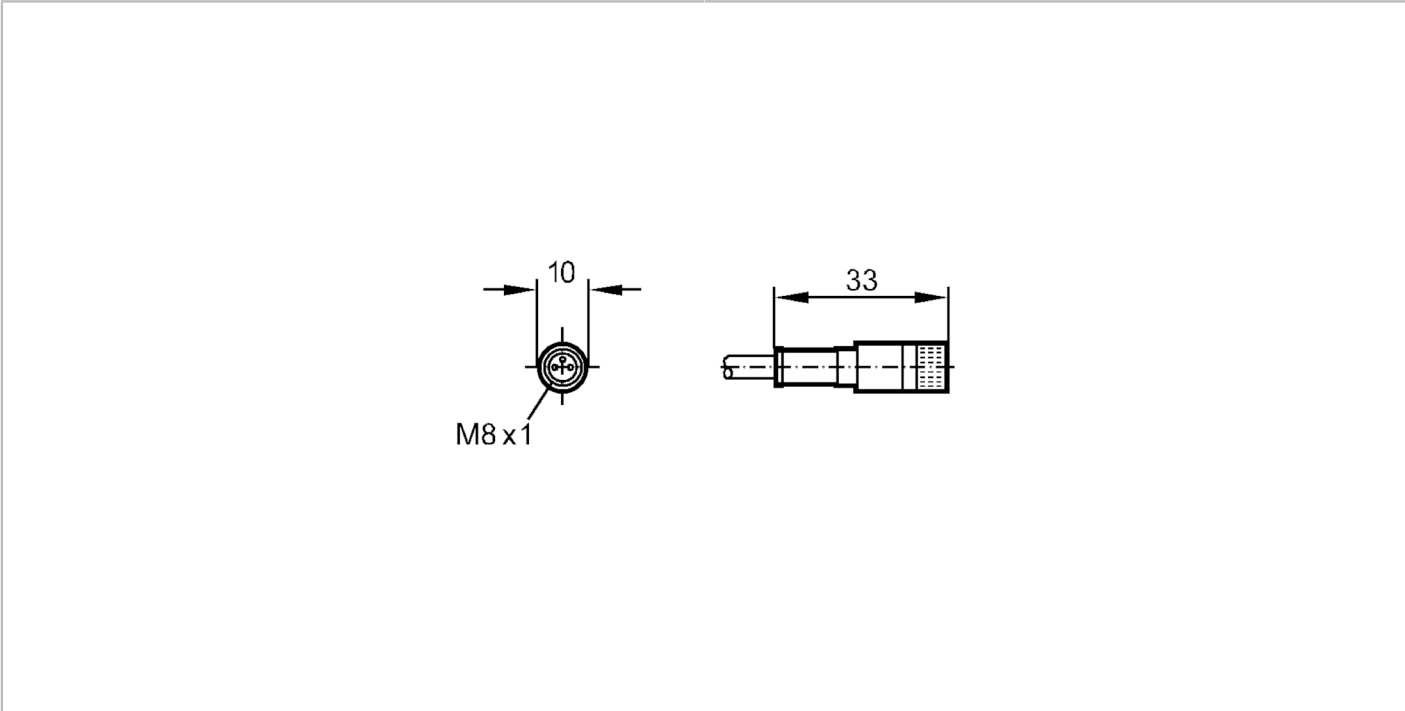

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Dimensions	[mm]	10 x 10 x 33
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel (1.4305 / 303)

Remarks		
Pack quantity		1 pcs.

Electrical connection		
Cable: 10 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)		

Electrical connection - socket		
Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)		

 

E10944



Connecting cable with socket

ADOGF030VAS0010A03

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue