


Connecting cable with socket

ADOAK190MSS0005B19

Article no longer available - archive entry

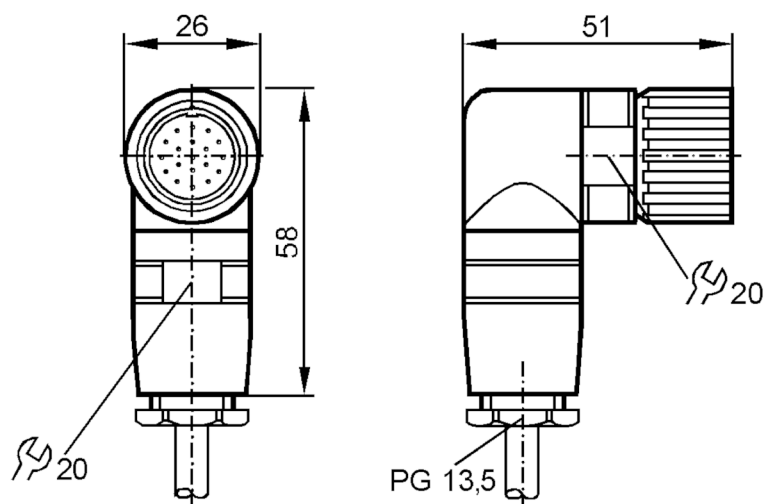

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 65
------------	-------

Mechanical data

Dimensions	[mm]	51 x 26 x 58
------------	------	--------------

Materials	brass nickel-plated
-----------	---------------------

Moulded-body material	brass, nickel-plated
-----------------------	----------------------

Material nut	brass, nickel-plated
--------------	----------------------

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, black, Ø 11 mm; 16 x 0.5 mm² (64 x Ø 0.1 mm) + 3 x 1.0 mm² (128 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M23; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

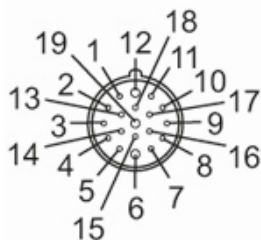

E10947



Connecting cable with socket

ADOAK190MSS0005B19

Connection

1	VT
2	RD
3	GY
4	RD/BU
5	GN
6	BU
7	GY/PK
8	WH/GN
9	WH/YE
10	WH/GY
11	BK
12	GN/YE
13	YE/BN
14	BN/GN
15	WH
16	YE
17	PK
18	GY/BN
19	BN

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow