

E10954




Connecting cable with socket

ADOGH050VAS0005E05

Article no longer available - archive entry

Alternative articles: EVT010
When selecting an alternative article and accessories please note that technical data may differ!

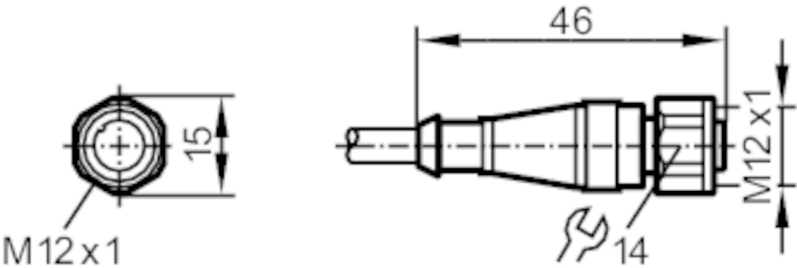

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...100
Protection		IP 68
Mechanical data		
Dimensions	[mm]	15 x 15 x 46
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10954



Connecting cable with socket


ADOGH050VAS0005E05

Electrical connection


Cable: 5 m, PVC, orange, Ø 5.6 mm; 5 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

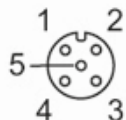

Connection

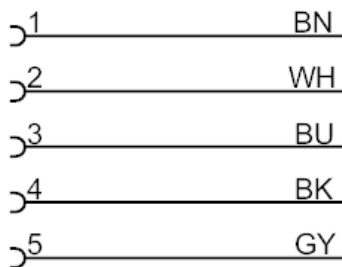

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white