


Connecting cable with socket

ADOGH050SCS0005I05

Article no longer available - archive entry

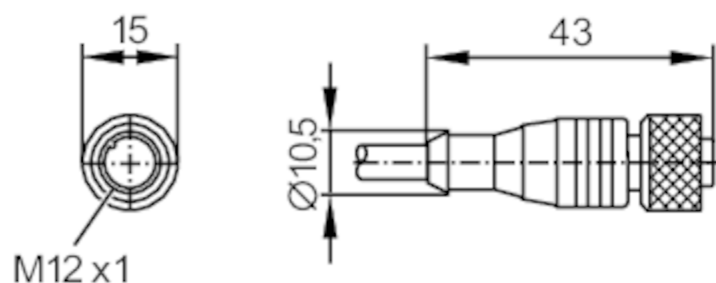

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter

Remarks

Pack quantity	1 pcs.
---------------	--------

E10961



Connecting cable with socket


ADOGH050SCS0005I05

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 5.5 mm; cross-linked; 5 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm

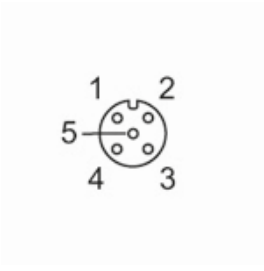

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white