




Connecting cable with socket

ADOAH080MSS0002A06

Article no longer available - archive entry

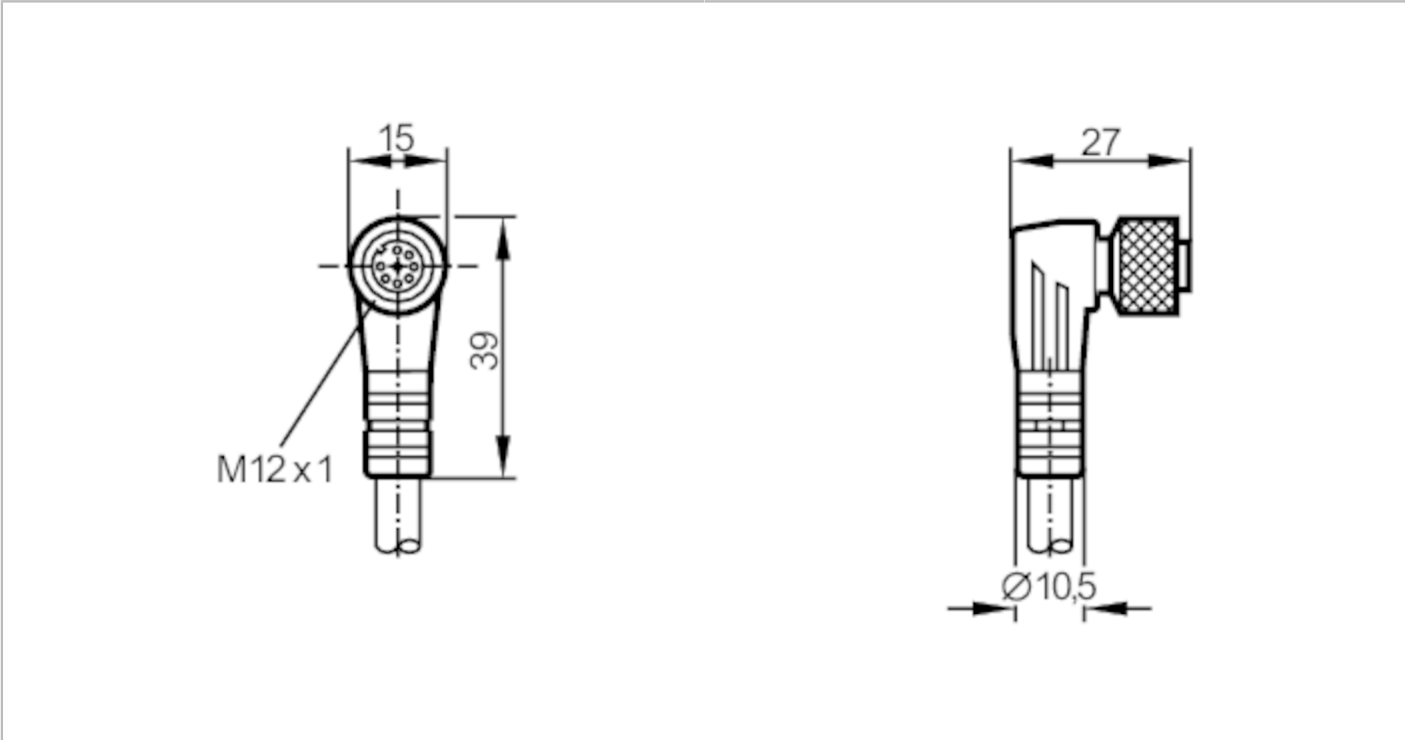


Electrical data		
Operating voltage	[M]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection

Cable: 2 m, PUR / PVC, black; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

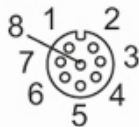


E10978



Connecting cable with socket

ADOAH080MSS0002A06

Connection

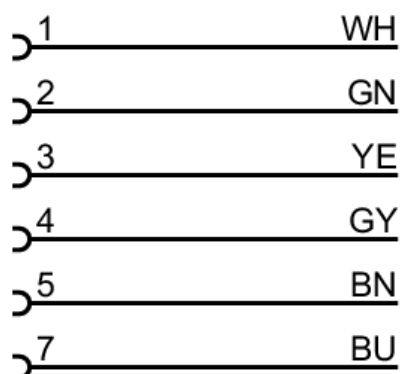

BN =	Core colours :	brown
BU =		blue
GN =		green
GY =		grey
WH =		white
YE =		yellow