




Connection cable

VDOGH040MSS00,6H04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC026
When selecting an alternative article and accessories please note that technical data may differ!

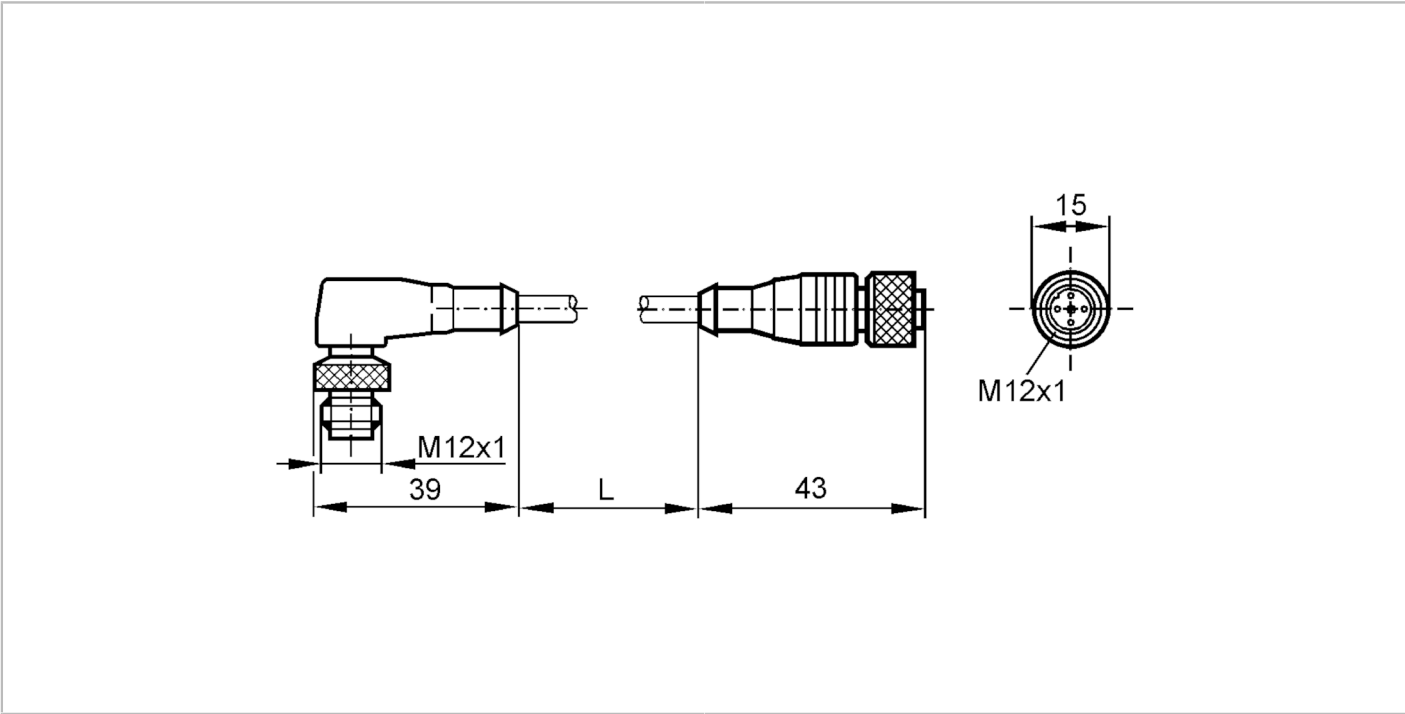

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E10982



Connection cable

VDOGH040MSS00,6H04STAH040MSS

Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

